



NORGREN EXCELON® FILTER-REGULATOR-LUBRICATOR COMBINATION UNITS

C72A-2AK-AL3-RMG-QLN
£84

- True Modularity with Norgren Quikclamp® Connections
- Compact Design
- Filter Removes Liquids and Solid Particles Down to 5 µm
- Push-to-Lock Adjusting Knob with Tamper Resistant Option
- Micro-Fog Lubricator Provides Air Line Lubrication to One or More Air Driven Tools or Other Devices
- Nearly Constant Oil Density Output with Varying Air Flow
- Can be Disassembled Without the Use of Tools or Removal from Air Line



C74A

C74A-3AK-AD3-RMG-QDN, £168, shown smaller than actual size.

SPECIFICATIONS

Fluid: Compressed Air

Maximum Pressure:

Transparent Bowl: 150 psig (10 bar)

Metal Bowl:

Manual or Semiautomatic Drain: 250 psig (17 bar)

Automatic Drain: 150 psig (10 bar)

Operating Temperature*:

Transparent Bowl: -20 to 50°C (0 to 125°F)

Metal Bowl: -20 to 65°C (0 to 150°F)

Particle Removal: 5 or 40 µm filter element

MATERIALS

Body: Zinc

Bonnet: Acetal

Regulator Bottom Plug: Acetal

Transparent Bowl: Polycarbonate

Guard: Zinc

Metal: Zinc

Metal Bowl Liquid Level

Indicator Lens: Transparent nylon

Sight Feed Dome: Transparent nylon

Element: Sintered polypropylene


Elastomers: Neoprene and nitrile

* Air supply must be dry enough to avoid ice formation at temperatures below 2°C (35°F).



C72A

C72A-3AK-AL3-RMG-QLN, £85, shown smaller than actual size.

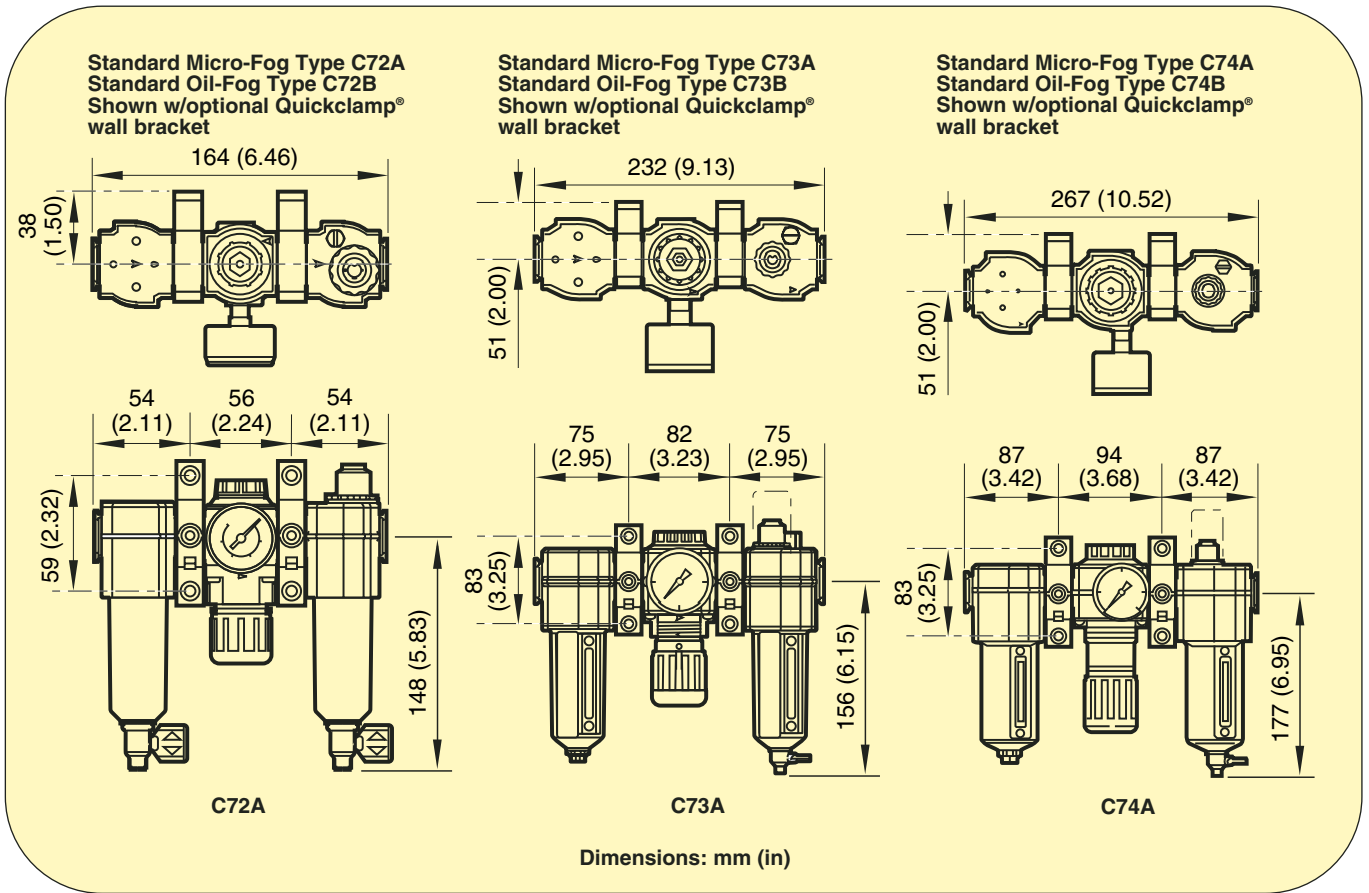

To Order (Specify Model Number)		MOST POPULAR MODELS HIGHLIGHTED!			
MODEL NO.	PRICE	PORT SIZE (in)	COMBINATION TYPE	WEIGHT kg (lb)	
C72A-2AK-AL3-RMG-QLN	£84	¼	Standard micro-fog filter-regulator-lubricator combo	1.47 (3.23)	
C72A-3AK-AL3-RMG-QLN	85	⅜	Standard micro-fog filter-regulator-lubricator combo	1.47 (3.23)	
C73A-2AK-AD3-RMG-QDN	132	¼	Standard micro-fog filter-regulator-lubricator combo	1.98 (4.36)	
C73A-3AK-AD3-RMG-QDN	132	⅜	Standard micro-fog filter-regulator-lubricator combo	1.98 (4.36)	
C73A-4AK-AD3-RMG-QDN	132	½	Standard micro-fog filter-regulator-lubricator combo	1.98 (4.36)	
C74A-3AK-AD3-RMG-QDN	168	⅜	Standard micro-fog filter-regulator-lubricator combo	2.82 (6.22)	
C74A-4AK-AD3-RMG-QDN	168	½	Standard micro-fog filter-regulator-lubricator combo	2.74 (6.04)	

Notes: Models include PTF threads. Filter includes automatic drain, transparent bowl without guard and a 40 µm filter element. Lubricator is a micro-fog model with ¼ turn manual drain and transparent bowl without guard.

Ordering Examples: C73A-2AK-AD3-RMG-QDN, combination filter-regulator-lubricator, includes a standard micro-fog lubricator with ¼" PTF ports, knob pressure adjustment, automatic filter drain, metal filter bowl with liquid level indicator, 40 µm filter, relieving diaphragm, 5 to 150 psig regulating spring, with regulator gauge manual ¼ turn drain and transparent lubricator bowl without guard, **£132**.

C74A-3AK-AD3-RMG-QDN, combination filter-regulator-lubricator, includes a standard micro-fog lubricator with ⅜" PTF ports, knob pressure adjustment, automatic filter drain, metal filter bowl with liquid level indicator, 40 µm filter, relieving diaphragm, 5 to 150 psig regulating spring, manual ¼ turn drain and metal lubricator bowl with liquid level indicator, **£168**.

See accessories listing on page C-108.



UNITED STATES

www.omega.com

1-800-TC-OMEGA

Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)

1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany

0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England

0800-488-488

FRANCE

www.omega.fr

088-466-342

CZECH REPUBLIC

www.omegaeng.cz

Karviná, Czech Republic

596-311-899

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters