



# TYPE 4 ENVIROLINE<sup>®</sup> SERIES TWO-DOOR STEEL ENCLOSURES

Starts at  
**\$1429**



SCE-60EL4812LP, \$1429,  
shown smaller than actual size.

- 0.104" Carbon Steel
- Seams Continuously Welded and Ground Smooth
- Oil-Resistant Gasket
- Flange Trough Collar Around All Sides of Door Opening
- Concealed Hinge
- Removable and Inchangeable Doors
- Black Quarter Turn Latches
- Removable Print Pocket
- Lifting Eyes for Easy Handling
- Ground Studs on Door and Body
- Collar Studs Provided for Mounting Optional Panels
- 12" Removable Floor Stands
- Removable Centerposts
- No Door Stiffeners Required
- Padlocking or Keylocking Handle with 3-Point Operating Mechanism and Tamper-Resistant Hardware is Available
- Provision for Mechanical Interlock
- Interchangeable Latches and Handles Available

## Application


Designed to house electrical and electronic controls, instruments and components. Provides protection from dust, oil and water. For outdoor application a drip shield is recommended.

## Finish



ANSI-61 gray powder coating inside and out over phosphatized surfaces. Optional panels are powder coated white.

## Industry Standards

NEMA Type 4, 12 & 13  
UL Listed Type 4 & 12  
CSA Type 4 & 12  
IEC 60529 IP66

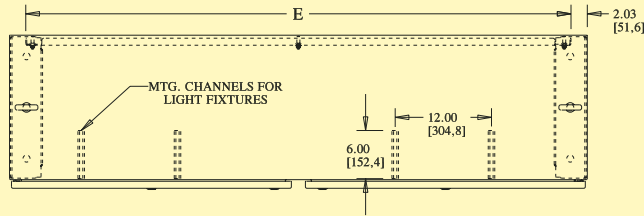

LATCH NOTE:  
Omit center latch top and bottom of door when door width is  $\leq 30.00$  [762]

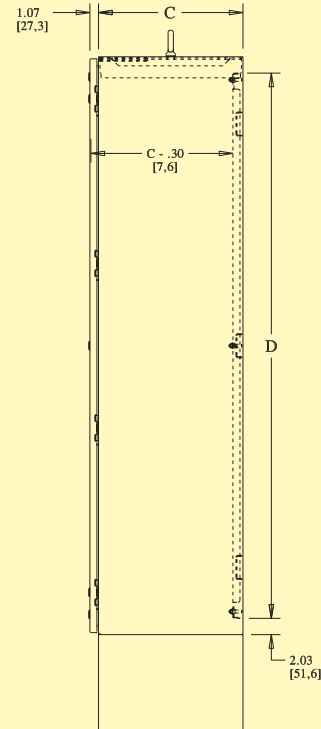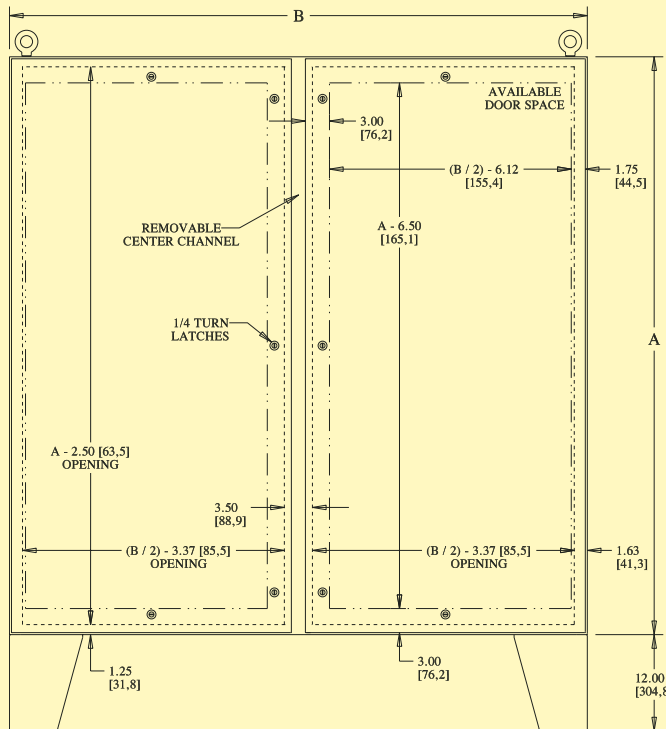

Dimensions: in (mm)

TYPE 4 ENVIROLINE TWO-DOOR ENCLOSURE

## To Order (Specify Model Number)

**IN STOCK FOR FAST DELIVERY!**

### TYPE 4 ENVIROLINE SERIES TWO-DOOR ENCLOSURES

ENCLOSURES (in)					SUB-PANEL (in)			
MODEL NO.	PRICE	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	PRICE	HEIGHT (D)	WIDTH (E)
SCE-60EL4812LP	\$1429	60.00	48.00	12.00	SCE-60P48	\$202	56.00	44.00
SCE-60EL4818LP	1457	60.00	48.00	18.00	SCE-60P48	202	56.00	44.00
SCE-60EL6012LP	1566	60.00	60.00	12.00	SCE-60P60	250	56.00	56.00
SCE-60EL6018LP	1595	60.00	60.00	18.00	SCE-60P60	250	56.00	56.00
SCE-72EL6012LP	1751	72.00	60.00	12.00	SCE-72P60	298	68.00	56.00
SCE-72EL6018LP	1733	72.00	60.00	18.00	SCE-72P60	298	68.00	56.00
SCE-72EL7212LP	1963	72.00	72.00	12.00	SCE-72P72	355	68.00	68.00
SCE-72EL7218LP	2015	72.00	72.00	18.00	SCE-72P72	355	68.00	68.00
SCE-72EL7224LP	2279	72.00	72.00	24.00	SCE-72P72	355	68.00	68.00

Ordering Example: SCE-60EL4812LP, Type 4 Enviroline® series two-door enclosure, \$1429.



#### UNITED STATES

[www.omega.com](http://www.omega.com)  
1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)  
Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)  
Deckenpfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)  
Manchester, England  
0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)  
Guyancourt, France  
088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)  
Karviná, Czech Republic  
596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)  
Amstelveen, NL  
0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters