



TYPE 12 LARGE CONTINUOUS HINGE ENCLOSURES



SCE-20C16ALP,
\$201, shown smaller
than actual size.



- 0.075" Carbon Steel
- Seams Continuously Welded and Ground Smooth, No Holes or Knockouts
- Continuous Hinge
- Rivnut/Screw Fastened Cover
- Oil Resistant Gasket
- Studs for Mounting Optional Panels
- Ground Stud on Door
- Removable Print Pocket Furnished if Height and Width of Enclosure is 24" or More

Application




Designed for use as electrical junction boxes, terminal wiring boxes, instrument housings, and electrical control enclosures. Provides protection from dust, oil and water.

Finish

ANSI-61 gray powder coating inside and out over phosphatized surfaces. Optional panels are powder coated white.

Industry Standards

NEMA Type 12 & Type 13; UL Listed Type 12;
CSA Type 1; IEC 60529 IP 55

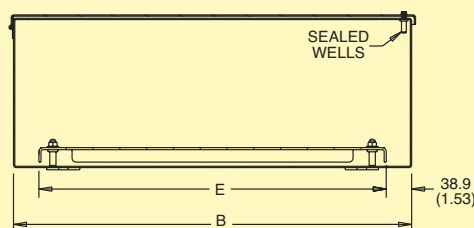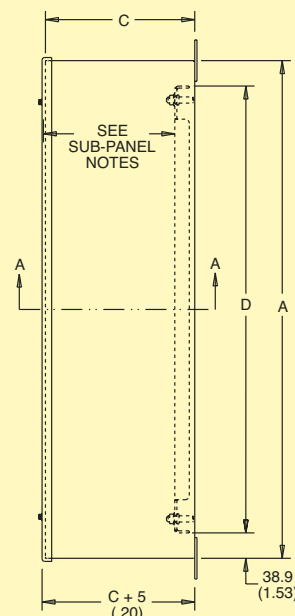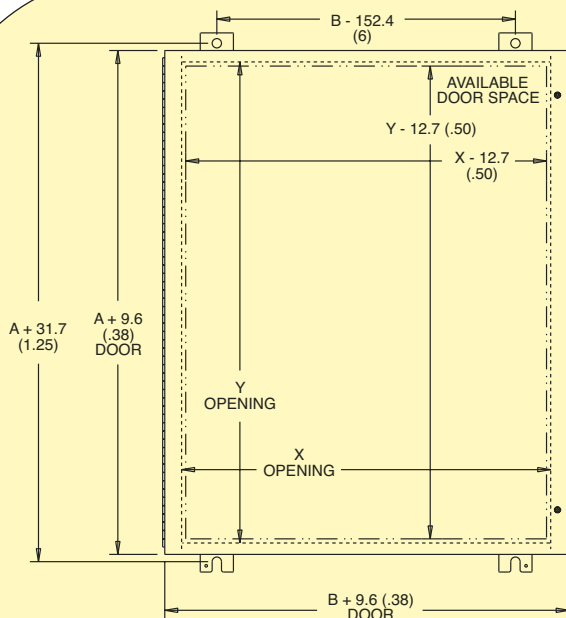

SECTION A-A

SUB-PANEL NOTES:
Dimensions are from the inside of the door
C - 14.7 (.58) for flat sub-panels
C - 27.4 (1.08) for bent sub-panels

OPENING NOTES:
Y = A - 44.7 (1.76) and,
X = B - 44.7 (1.76) for SCE-20C16ALP only.

Y = A - 25.4 (1) and,
X = B - 44.7 (1.76) when B is ≤ 610 (24)

Y = A - 70.1 (2.76) and,
X = B - 70.1 (2.76) when B is ≤ 610 (24)

Dimensions: mm (in)

To Order (Specify Model Number)

MOST POPULAR MODELS HIGHLIGHTED!

TYPE 12 LARGE CONTINUOUS HINGE ENCLOSURES

ENCLOSURES (in)					SUB-PANEL (in)			
MODEL NO.	PRICE	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	PRICE	HEIGHT (D)	WIDTH (E)
SCE-20C16ALP	\$201	20.00	16.00	7.00	SCE-20P16	\$30	17.00	13.00
SCE-20C16BLP	215	20.00	16.00	9.00	SCE-20P16	30	17.00	13.00
SCE-20C20ALP	223	20.00	20.00	7.00	SCE-20P20	35	17.00	17.0
SCE-20C20BLP	239	20.00	20.00	9.00	SCE-20P20	35	17.00	17.00
SCE-24C20ALP	244	24.00	20.00	7.00	SCE-24P20	45	21.00	17.00
SCE-24C20BLP	263	24.00	20.00	9.00	SCE-24P20	45	21.00	17.00
SCE-24C24ALP	269	24.00	24.00	7.00	SCE-24P24	53	21.00	21.00
SCE-24C24BLP	289	24.00	24.00	9.00	SCE-24P24	53	21.00	21.00
SCE-24C24CLP	326	24.00	24.00	11.00	SCE-24P24	53	21.00	21.00
SCE-30C20ALP	275	30.00	20.00	7.00	SCE-30P20	55	27.00	17.00
SCE-30C20BLP	295	30.00	20.00	9.00	SCE-30P20	55	27.00	17.00
SCE-30C24ALP	305	24.00	20.00	7.00	SCE-30P24	63	27.00	21.00
SCE-30C24BLP	356	30.00	24.00	9.00	SCE-30P24	63	27.00	21.00
SCE-30C24DLP	371	36.00	24.00	13.00	SCE-30P24	63	27.00	21.00
SCE-36C24ALP	343	36.00	24.00	7.00	SCE-36P24	75	33.00	21.00
SCE-36C24BLP	368	36.00	24.00	9.00	SCE-36P24	75	33.00	21.00
SCE-36C24CLP	391	36.00	24.00	11.00	SCE-36P24	75	33.00	21.00
SCE-36C30BLP	421	36.00	30.00	9.00	SCE-36P30	101	33.00	27.00
SCE-36C30DLP	474	36.00	30.00	13.00	SCE-36P30	101	33.00	27.00
SCE-48C36CLP	596	48.00	36.00	11.00	SCE-48P36	154	45.00	33.00

Ordering Example: SCE-20C16ALP Type 12, large, continuous hinge enclosure, \$201.



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488

FRANCE

www.omega.fr

Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz

Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl

Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters