




TYPE 4X 304 AND 316 SS TWO-DOOR ENCLOSURES

Starts at
\$7327

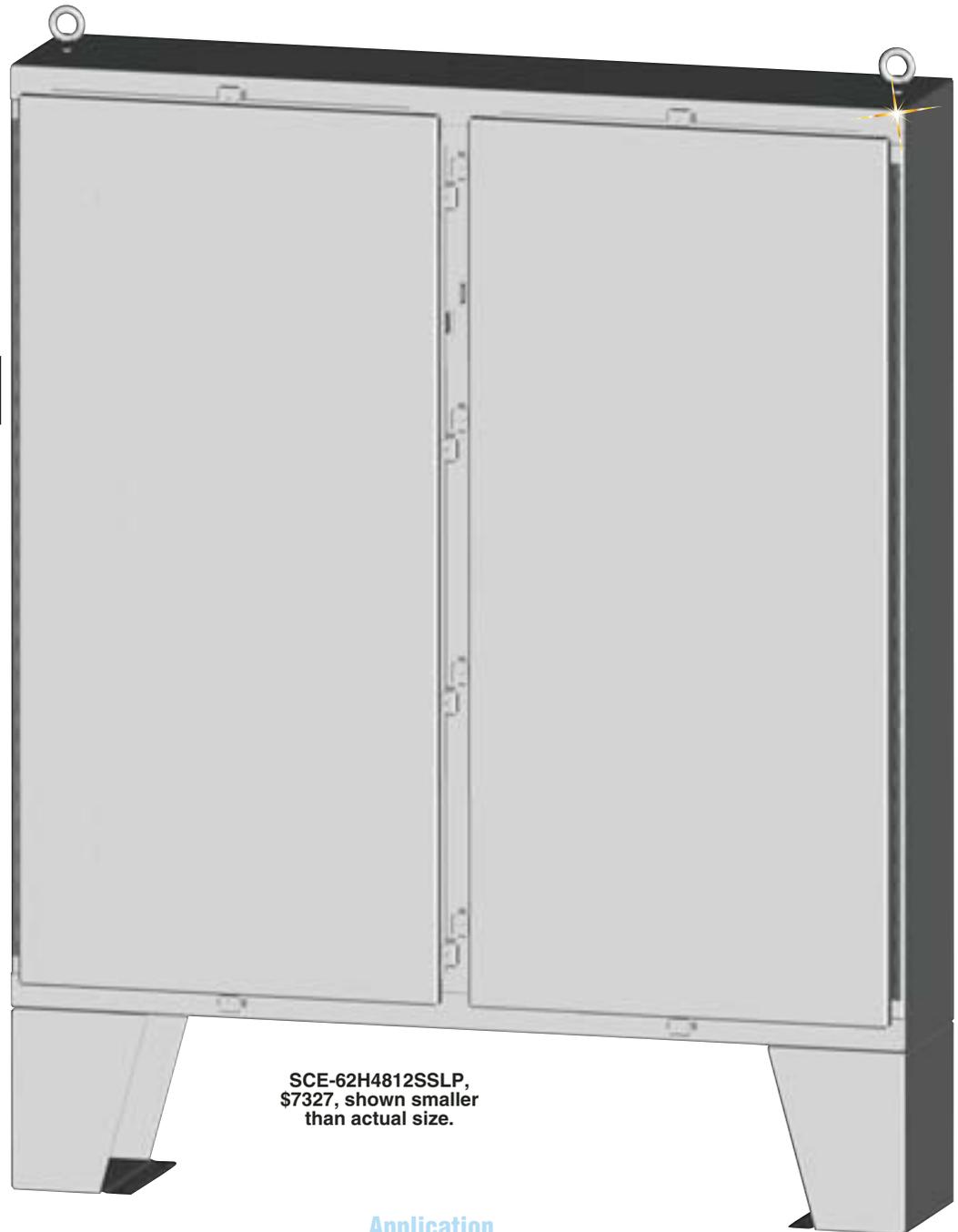

SCE-62H4812SSLP,
\$7327, shown smaller
than actual size.

- 0.104" Stainless Steel Type 304 and 316
- Seams Continuously Welded and Ground Smooth
- Stainless Steel Concealed Hinge
- Flange Trough Collar Around All Sides of Door Opening
- Interior Print Pocket
- Oil-Resistant Gasket
- Ground Stud On Door
- 12" Removable Floor Stands
- Hasp and Staple for Padlocking
- Removable Center Post
- Panel Supports
- Heavy Duty Lifting Eyes
- Stainless Steel Clamps On 3 Sides of Door
- No Door Stiffener Required
- Collar Studs Provided for Mounting Optional Sub-Panels

Application


Designed to house electrical equipment in damp and wet areas, corrosive atmospheres and for outdoor applications. For outdoor application a drip shield is recommended.

Finish

#4 brushed finish on all exterior surfaces. Optional panels are powder coated white.

Industry Standards

NEMA Type 4, 4X, 12 & 13; UL Listed Type 4, 4X & 12;
CSA Type 4, 4X & 12; IEC 60529 IP 66

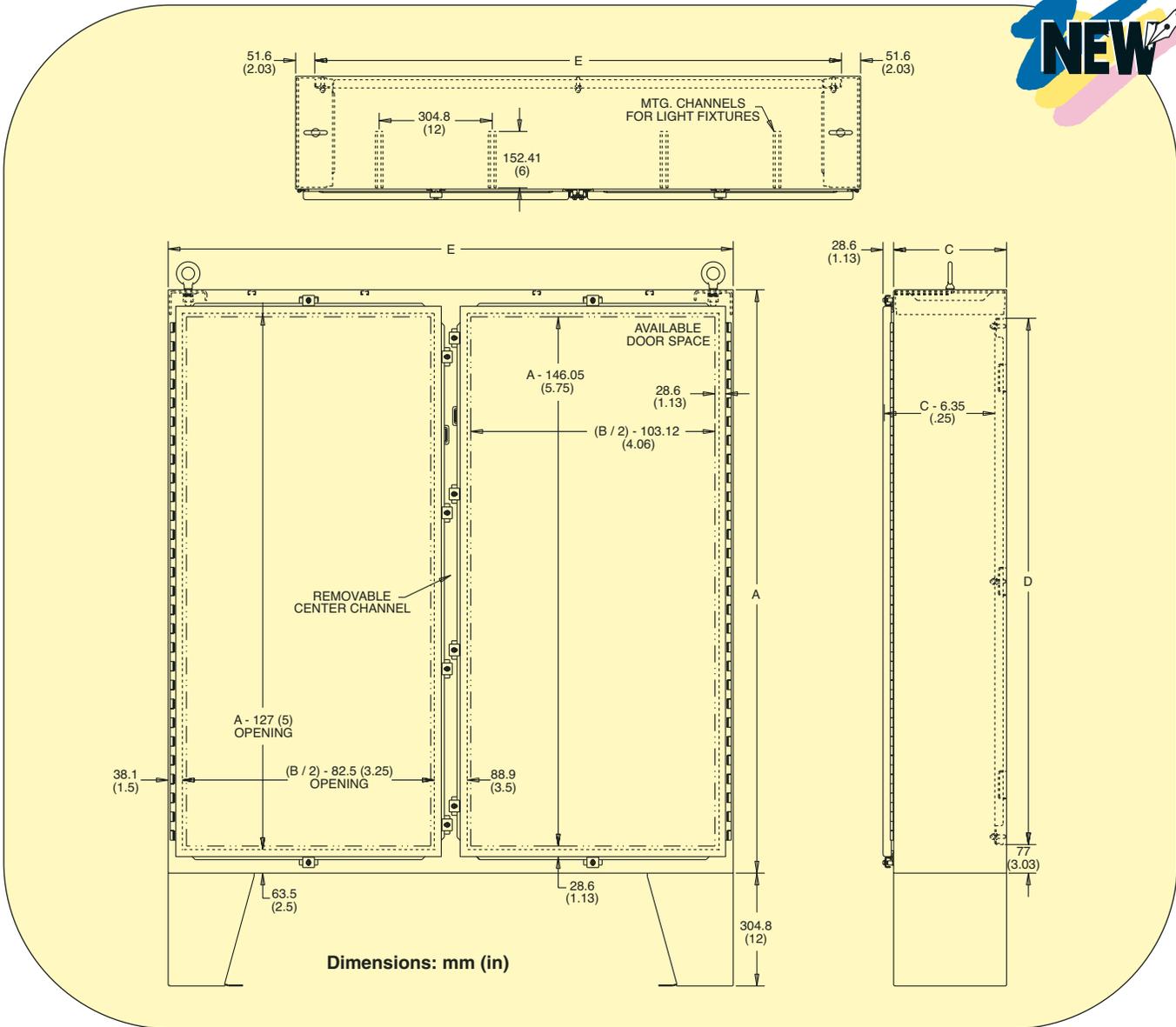

To Order (Specify Model Number)

IN STOCK FOR FAST DELIVERY!

TYPE 4X TWO-DOOR 304 STAINLESS STEEL ENCLOSURES

ENCLOSURES (in)					SUB-PANEL (in)			
MODEL NO.	PRICE	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	PRICE	HEIGHT (D)	WIDTH (E)
SCE-62H4812SSLP	\$7327	62.00	48.00	12.00	SCE-60P48	\$268	56.00	44.00
SCE-62H6012SSLP	8218	62.00	60.00	12.00	SCE-60P60	331	56.00	56.00
SCE-74H6012SSLP	9859	74.00	60.00	12.00	SCE-72P60	394	68.00	56.00
SCE-74H7212SSLP	10,123	74.00	72.00	12.00	SCE-72P72	470	68.00	56.00
SCE-74H7224SSLP	12,900	74.00	72.00	24.00	SCE-72P72	470	68.00	68.00

TYPE 4X TWO-DOOR 316 STAINLESS STEEL ENCLOSURES

ENCLOSURES (in)					SUB-PANEL (in)			
MODEL NO.	PRICE	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	PRICE	HEIGHT (D)	WIDTH (E)
SCE-62H4812SS6LP	\$8792	62.00	48.00	12.00	SCE-60P48	\$268	56.00	44.00
SCE-62H6012SS6LP	9862	62.00	60.00	12.00	SCE-60P60	331	56.00	56.00
SCE-74H6012SS6LP	11,831	74.00	60.00	12.00	SCE-72P60	394	68.00	56.00
SCE-74H7212SS6LP	12,147	74.00	72.00	12.00	SCE-72P72	470	68.00	68.00
SCE-74H7224SS6LP	15,480	74.00	72.00	24.00	SCE-72P72	470	68.00	68.00

Ordering Example: SCE-62H4812SSLP Type 4X two-door, 304 stainless steel enclosure, \$7327.



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters