


Jack Panels

JACK PANEL CONDUIT BOX WITH 3 MTP CONNECTORS

- CALIBRATION — K AND U
- CONNECTOR TYPE — STANDARD ROUND FACE MALE AND FEMALE CONNECTORS


OSK5076
\$97 each
 Plus One-Time Set-Up Charge

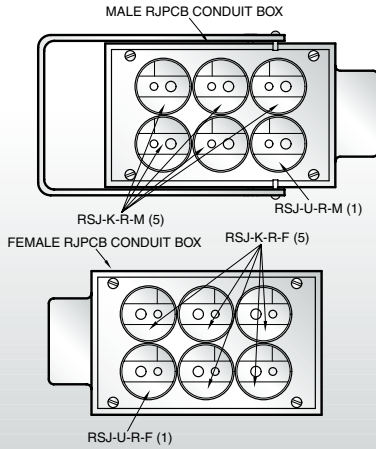

JACK PANEL CONDUIT BOXES WITH 5 FEMALE CONNECTORS AND BLACK SNAP ACTION HANDLE

- CALIBRATION — J
- CONNECTOR TYPE — STANDARD ROUND FEMALE CONNECTORS
- SPECIAL OPTIONS — SNAP ACTION HANDLE


OSK1342
\$40 each
 Plus One-Time Set-Up Charge

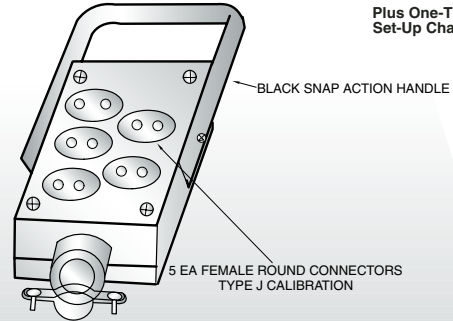

JACK PANEL CONDUIT BOX WITH 3 CONNECTORS INSTEAD OF 5

- CALIBRATION — R/S
- CONNECTOR TYPE — STANDARD FEMALE PANEL JACKS
- SPECIAL OPTIONS — 3 STANDARD CONNECTORS INSTEAD OF 5


OSK0395
\$40 each
 Plus One-Time Set-Up Charge

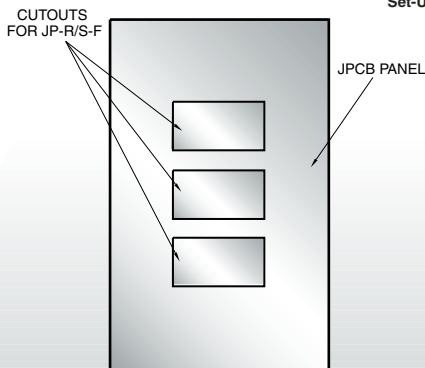

JACK PANEL CONDUIT BOX WITH SPECIAL HIGH TEMPERATURE PANELS

- CALIBRATION — U
- CONNECTOR TYPE — ULTRA HIGH TEMPERATURE CERAMIC FEMALE CONNECTOR
- SPECIAL OPTIONS — HIGH TEMPERATURE STEEL JACK PANEL


OSK2278
\$253 each
 Plus One-Time Set-Up Charge

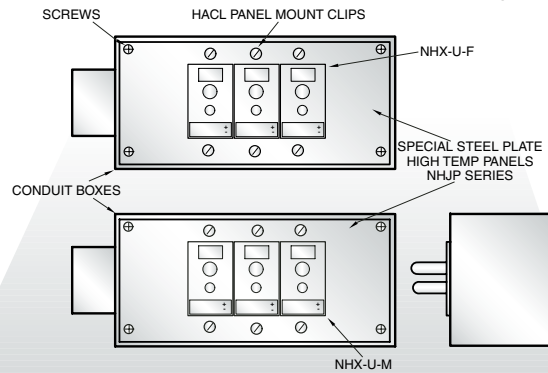

FEMALE JACK PANEL CONDUIT BOX WITH 2 CERAMIC CONNECTORS

- CALIBRATION — K
- CONNECTOR TYPE — ULTRA HIGH TEMPERATURE CERAMIC FEMALE CONNECTOR
- SPECIAL OPTIONS — 2 JACK CONNECTORS


OSK2859
\$70 each
 Plus One-Time Set-Up Charge

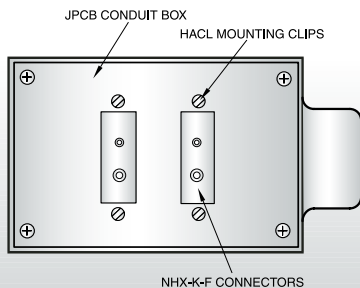

JACK PANEL CONDUIT BOXES WITH NHX CONNECTORS

- CALIBRATION — J
- CONNECTOR TYPE — HIGH TEMPERATURE CERAMIC FEMALE AND MALE JACKS
- WIRE AWG — 20
- WIRE LENGTH — 6 IN FOR FEMALE CONDUIT BOX, 60 IN FOR MALE CONDUIT BOX
- WIRE INSULATION — GLASS ON GLASS
- TERMINATION — HIGH TEMPERATURE CERAMIC MALE AND FEMALE CONNECTORS


OSK4356
\$196 each
 Plus One-Time Set-Up Charge

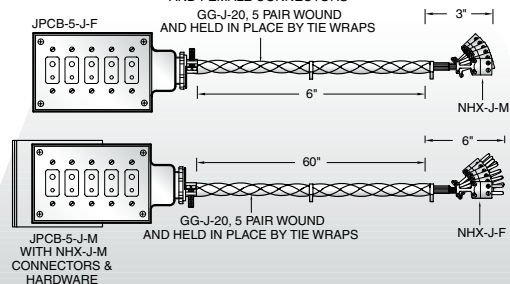

19" PANEL WITH CUTOUTS FOR 40 SPJ'S, 5" SELECTOR SWITCH AND METER


- CALIBRATION — USE WITH TYPE U CONNECTORS
- CONNECTOR TYPE — USE WITH STANDARD PANEL JACKS
- SPECIAL OPTIONS — ROTATED METER CUTOUT

ISK5147
\$315 each
 Plus One-Time Set-Up Charge

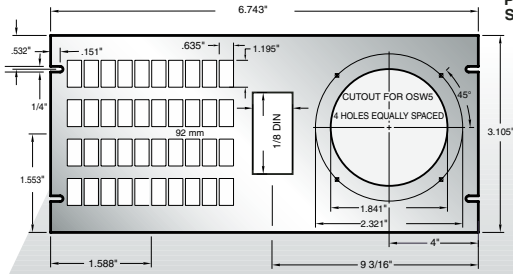


CUSTOM PANEL

NSK1011-A
\$185 each
 Plus One-Time Set-Up Charge

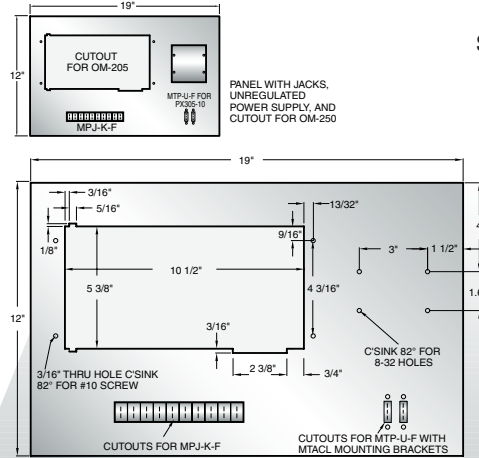


BLANK PANEL WITH STANDARD MOUNTING HOLES

NSK1011
\$40 each
 Plus One-Time Set-Up Charge

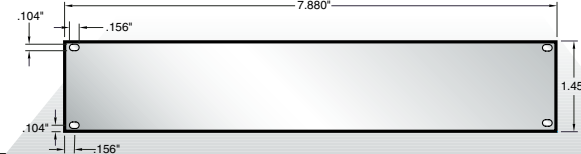


PANEL WITH TWO 1/8 DIN AND STANDARD 3" AND 5" ROTARY SELECTOR SWITCHES

OSK1389
\$125 each
 Plus One-Time Set-Up Charge

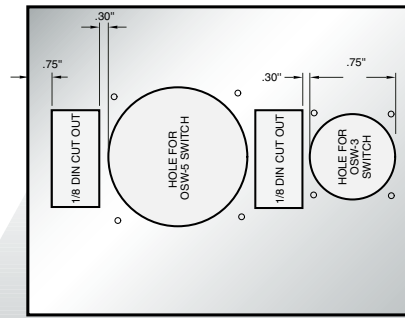

HIGH TEMPERATURE JACK PANEL


OSK2109
\$164 each
 Plus One-Time Set-Up Charge

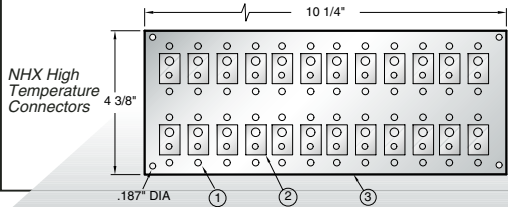

PANEL WITH 6 ROWS OF COMBINED CALIBRATIONS OF MINIATURE PANEL JACKS

OSK1105A
\$450 each
 Plus One-Time Set-Up Charge


- CALIBRATION — J
- CONNECTOR TYPE — FEMALE STANDARD PANEL JACKS
- WIRE AWG — 24 STRANDED
- WIRE INSULATION — PFA ON PFA
- TERMINATION — SUB-D TYPE MALE CONNECTORS W/ 37 IRON MULTIPINS

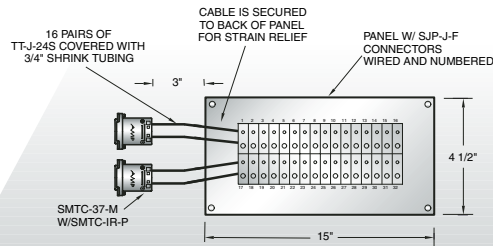

PANEL WITH 2 ROWS EACH OF 10 CUTOUTS FOR SPJ'S

- CALIBRATION — USE WITH K, T, J, E, OR U CONNECTORS
- CONNECTOR TYPE — STANDARD PANEL JACKS


OSK1150
\$135 each
 Plus One-Time Set-Up Charge

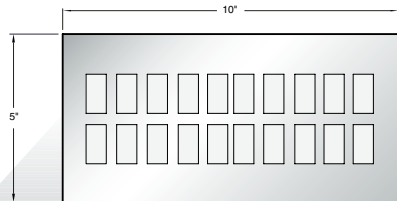

PANEL WITH 6 ROWS OF COMBINED CALIBRATIONS OF MINIATURE PANEL JACKS

- CALIBRATION — K AND T
- CONNECTOR TYPE — UNIVERSAL TC CONNECTOR
- SPECIAL OPTIONS — USES SACL BRACKETS

OSK0487
\$162 each
 Plus One-Time Set-Up Charge

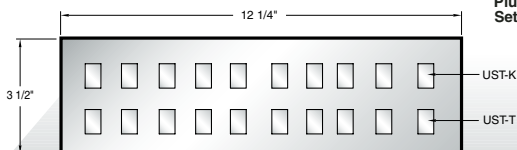

12 x 5 1/4" PANEL WITH CUT-OUTS

OSK2265
\$63 each
 Plus One-Time Set-Up Charge

