

# Wire

Dimensions: mm (in)

## TWISTED THERMOCOUPLE WIRE

- CALIBRATION — T
- WIRE AWG — 24 SOLID
- WIRE INSULATION — PFA
- SPECIAL OPTIONS — TWISTED SINGLE CONDUCTORS


**OSK50195**  
**\$340/300 m (1000') Spool**  
 Plus One-Time Set-Up Charge



## 20 AWG STRANDED CU/CU WITH PC INSULATION

- CALIBRATION — T
- WIRE AWG — 20 STRANDED
- WIRE INSULATION — PVC


**CSK4134**  
**\$2798/300 m (1000') Spool**  
 Plus One-Time Set-Up Charge

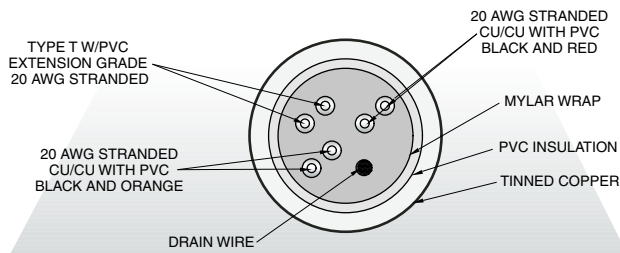

## THERMOCOUPLE WIRE WITH STAINLESS STEEL OVERBRAIDING AT HOT END

- CALIBRATION — E
- SHEATH LENGTH — 7.6 m (25 feet)
- WIRE AWG — 20
- WIRE LENGTH — 7.6 m (25 feet)
- WIRE INSULATION — PFA
- TERMINATION — BEADED


**OSK70327**  
**\$79 each**  
 Plus One-Time Set-Up Charge

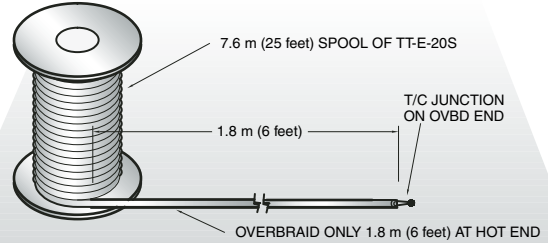

## 18 AWG HIGH TEMP GLASS INSULATED WIRE

- CALIBRATION — K
- SHEATH DIA. — 1.8 x 3 (0.070 x 0.120)
- WIRE AWG — 18
- WIRE INSULATION — HIGH TEMP GLASS
- TERMINATION — STRIPPED LEADS

 
**OSK2108**  
**\$325/300 m (1000') Spool**  
 Plus One-Time Set-Up Charge



## PFA INDIVIDUALLY INSULATED THERMOCOUPLE WIRE SPOOL

- CALIBRATION — T
- SHEATH DIA. — 1.8 x 2.8 (0.071 x 0.110)
- WIRE AWG — 24
- WIRE INSULATION — PFA INDIVIDUAL STRANDED
- TERMINATION — STRIPPED LEADS


**OSK50479**  
**\$281/300 m (1000') Spool**  
 Plus One-Time Set-Up Charge

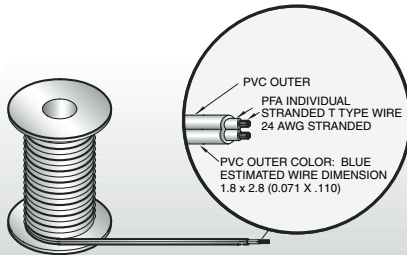

## GG T/C WIRE WITH NON-STANDARD COLOR BRAIDED JACKETS

- CALIBRATION — J, T, K, OR E
- WIRE AWG — ANY
- WIRE INSULATION — GLASS ON GLASS
- WIRE LENGTH — ANY
- SPECIAL OPTIONS — SPECIALLY COLOR BRAIDED JACKETS


**OSK5022**  
**\$150 each**  
 Plus One-Time Set-Up Charge

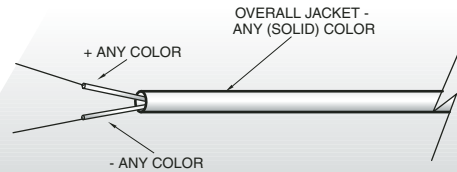

## PFA INSULATED WIRE WITH INCONEL OVERBRAID AND 16 STRANDED GAGE

- WIRE AWG — 16 STRANDED
- WIRE INSULATION — PFA WITH INCONEL OVERBRAID
- TERMINATION — STRIPPED LEADS


**OSK50673**  
**\$2275/300 m (1000') Spool**  
 Plus One-Time Set-Up Charge

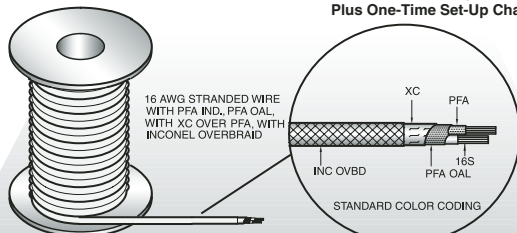

## FIBERGLASS SLEEVING WITH NEXTEL OVERBRAID

- CALIBRATION — B
- SHEATH MATERIAL — FIBERGLASS
- WIRE AWG — 24
- WIRE INSULATION — NEXTEL OVERBRAID

**OSK1736**  
**\$28 each**  
 Plus One-Time Set-Up Charge

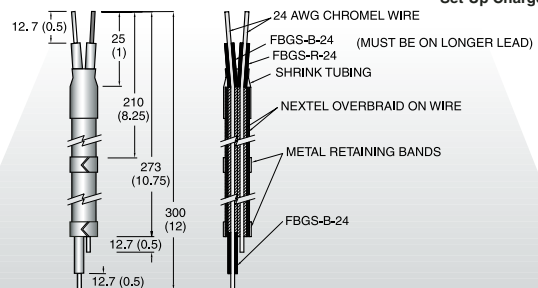


# Wire (cont'd)

## CUSTOM RS EXTENSION GRADE WIRE

- CALIBRATION — R/S
- WIRE AWG — 16 STAINLESS STEEL OVERBRAID
- WIRE INSULATION — PFA ON PFA, OR GLASS ON GLASS
- WIRE LENGTH — 1000 FT ON SPOOL


**OSK5020**  
**\$85 each**  
 Plus One-Time Set-Up Charge

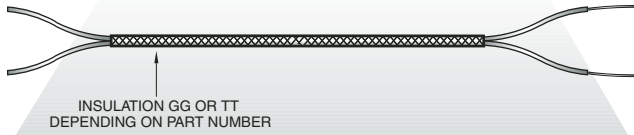

## 2-CONDUCTOR RTD WIRE WITH TINNED COPPER TWISTED OVER CONDUCTORS

- WIRE AWG — 24 STRANDED
- WIRE INSULATION — PFA
- WIRE LENGTH — ANY
- SPECIAL OPTIONS — TINNED COPPER OVERBRAID


**OSK3172**  
**\$492/1000' Spool**  
 Plus One-Time Set-Up Charge

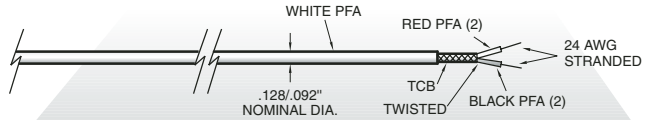

## CUSTOM RS EXTENSION GRADE WIRE

- CALIBRATION — R/S
- WIRE AWG — 16 EXTENSION GRADE
- WIRE LENGTH — 330 FT ON SPOOL
- WIRE INSULATION — GLASS ON GLASS BRAID


**OSK4119**  
**\$85 each**  
 Plus One-Time Set-Up Charge

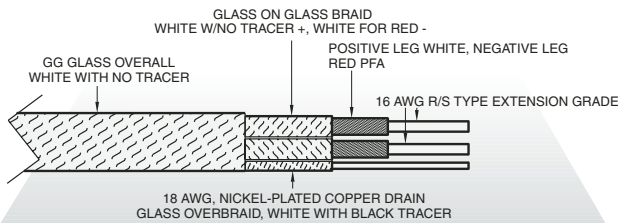

## 4-CONDUCTOR RTD OF STRANDED SILVER WIRE

- WIRE AWG — 19 SILVER STRANDED
- WIRE INSULATION — PFA
- WIRE LENGTH — ANY
- SPECIAL OPTIONS — SILVER PLATED OVERBRAID


**OSK3173**  
**\$660/1000' Spool**  
 Plus One-Time Set-Up Charge

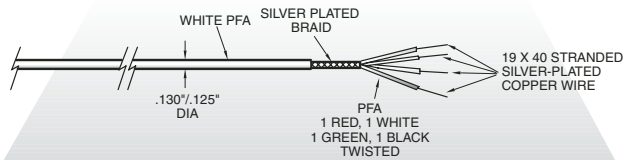

## 8-CONDUCTOR RTD WIRE WITH TINNED COPPER TWISTED OVER CONDUCTORS

- WIRE AWG — 26 STRANDED
- WIRE INSULATION — PFA
- WIRE LENGTH — ANY
- SPECIAL OPTIONS — TINNED COPPER OVERBRAID


**OSK5193**  
**\$1390/1000' Spool**  
 Plus One-Time Set-Up Charge

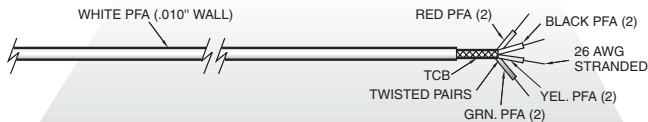

## TINNED COPPER SOLID WIRE WITH WHITE GLASS OVERBRAID AND BINDER

- WIRE AWG — 22
- WIRE INSULATION — WHITE GLASS OVERBRAID AND BINDER
- WIRE LENGTH — 1000 FT ON SPOOL


**OSK50291**  
**\$134 each**  
 Plus One-Time Set-Up Charge

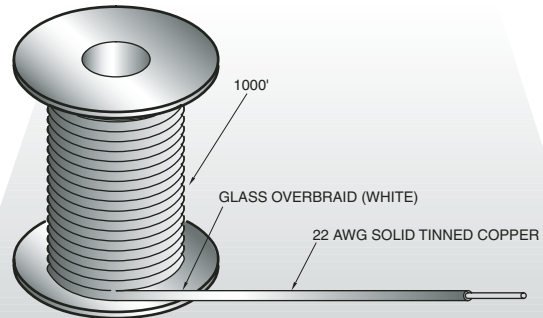

## E-GLASS INSULATED WIRE WITH ALUMEL LEGS ONLY

- WIRE AWG — 30
- WIRE INSULATION — E-GLASS (GLASS OVER GLASS)
- WIRE LENGTH — ANY
- SPECIAL OPTIONS — ALUMEL LEGS ONLY (NO CHROMEL)


**OSK1605**  
**\$240/1000' Spool**  
 Plus One-Time Set-Up Charge

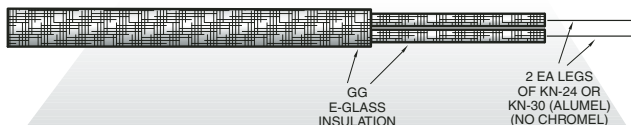

## PFA INSULATED TYPE K OVERBRAIDED WIRE

- CALIBRATION — K
- WIRE AWG — 24 STRANDED OVERBRAIDED
- WIRE INSULATION — PFA ON PFA
- WIRE LENGTH — ANY


**OSK4602**  
**\$705/1000' Spool**  
 Plus One-Time Set-Up Charge

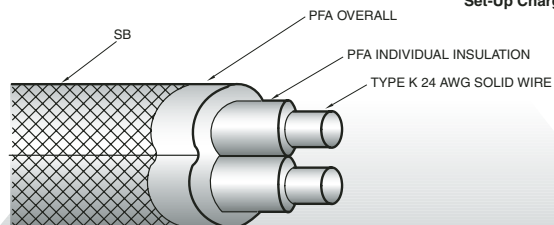

**SINGLE WIRE WITH GLASS BRAID INSULATION**

- WIRE AWG — 30
- WIRE INSULATION — GLASS OVERBRAID
- WIRE LENGTH — 1000 FT ON SPOOL


**OSK50098**  
**\$49/1000' Spool**  
 Plus One-Time Set-Up Charge

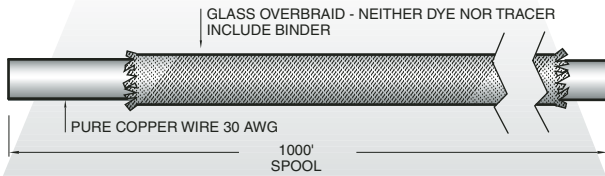

**SPECIAL LIMITS OF ERROR WIRE**

- CALIBRATION — T
- WIRE LENGTH — 500 FT
- WIRE AWG — 24 STRANDED
- WIRE INSULATION — PFA ON PFA
- SPECIAL OPTIONS — 12 TC WIRE PAIRS

 
**OSK60125**  
**\$5250/500' Spool**  
 Plus One-Time Set-Up Charge



**SINGLE LEG OF STRANDED CONSTANTAN WIRE WITH RED FEP INSULATION**

- WIRE AWG — 24 STRANDED
- WIRE INSULATION — RED FEP, TCB OVERBRAID, CLEAR FEP OVERALL
- WIRE LENGTH — 1000 FT ON SPOOL


**OSK50295**  
**\$325/1000' Spool**  
 Plus One-Time Set-Up Charge

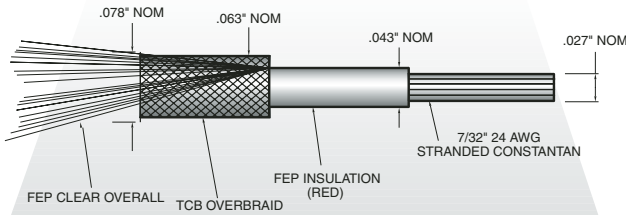

**SINGLE PAIR OF SOLID TYPE K TC WIRE WITH FEP INSULATION OVER EACH INDIVIDUAL CONDUCTOR AND TINNED COPPER OVERBRAID**

- CALIBRATION — K
- WIRE AWG — 20
- WIRE INSULATION — FEP INSULATION WITH TINNED COPPER OVERBRAID


**OSK3802**  
**\$335/500' Spool**  
 Plus One-Time Set-Up Charge

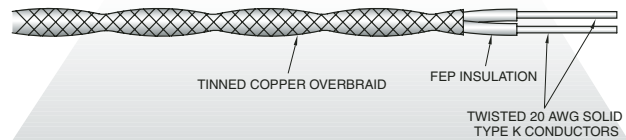

**MULTIPAIR EXTENSION WIRE WITH OVERBRAID**

- CALIBRATION — J, K, T, OR E
- WIRE LENGTH — ANY
- WIRE AWG — ANY
- WIRE INSULATION — ANY WITH MYLAR SHIELDING
- SPECIAL OPTIONS — STAINLESS STEEL, ICONEL, TINNED COPPER OVERBRAIDINGS AVAILABLE


**OSK1263**  
**\$1125/500' Spool**  
 Plus One-Time Set-Up Charge

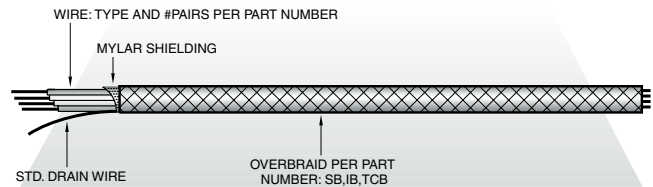

**MULTIPLE PAIRS OF WIRE WITHIN A SINGLE OVERBRAID**

- WIRE AWG — ANY
- WIRE INSULATION — ANY BUT WITH OVERALL OVERBRAID
- WIRE LENGTH — ANY
- SPECIAL OPTIONS — NO. OF OVERBRAIDED PAIRS IS SELECTABLE AS ARE INDIVIDUAL WIRES AND INSULATION


**OSK5112**  
 starting at  
**\$445**  
 Plus One-Time Set-Up Charge

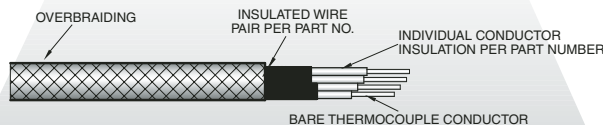

**PFA COATED AND SHIELDED 4-CONDUCTOR WIRE**

- WIRE LENGTH — ANY
- WIRE AWG — 32
- WIRE INSULATION — PFA ON PFA
- SPECIAL OPTIONS — 304 STAINLESS STEEL OVERBRAID CLEAR PFA OVERALL

**OSK3796**  
**\$555/1000' Spool**  
 Plus One-Time Set-Up Charge

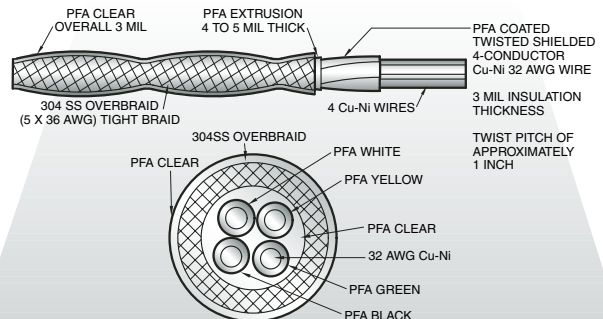


## Wire (cont'd)

### 6 PAIRS OF GLASS OVER GLASS INSULATED WIRE WITH SB BRAID

- CALIBRATION — J
- SHEATH LENGTH — 200'
- WIRE AWG — 20
- WIRE LENGTH — 200'
- WIRE INSULATION — GLASS


**OSK1489**  
**\$880/200' Spool**  
 Plus One-Time Set-Up Charge

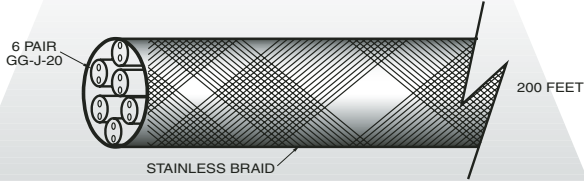

### SINGLE CONDUCTOR CLAD

- SHEATH DIA. — 1/8"
- SHEATH LENGTH — 100'

 
**OSK3466**  
**\$100 each**  
 Plus One-Time Set-Up Charge



### SLE MULTIPAIR WIRE

- CALIBRATION — T
- WIRE LENGTH — 500 FT
- WIRE AWG — 24 STRANDED
- WIRE INSULATION — PFA ON PFA
- SPECIAL OPTIONS — 12 TC WIRE PAIRS

 **OSK60125**  
**\$1050/100' Spool**  
 Plus One-Time Set-Up Charge



### 0.020 DIAMETER CLAD, 0.0015 DIAMETER WIRES

- SHEATH DIA. — .020"
- WIRE DIA — .0015"
- TERMINATION — STRIPPED LEADS


**OSK4381**  
**\$250/100' Spool**  
 Plus One-Time Set-Up Charge



### 4-CONDUCTOR RTD WIRE WITH TINNED COPPER TWISTED OVER CONDUCTORS

- WIRE AWG — 24 STRANDED
- WIRE INSULATION — PFA
- WIRE LENGTH — ANY
- SPECIAL OPTIONS — TINNED COPPER OVERBRAID

 **OSK5192**  
**\$720/1000' Spool**  
 Plus One-Time Set-Up Charge



### MULTIPAIR CABLE OF 6 PAIRS OF TYPE K TC WIRE

- CALIBRATION — K
- WIRE LENGTH — 30 FT
- WIRE AWG — 24
- WIRE INSULATION — PFA ON PFA
- SPECIAL OPTIONS — STAINLESS STEEL OVERBRAID


**OSK60739**  
**\$212/30' Spool**  
 Plus One-Time Set-Up Charge



### MULTIPAIR CABLE OF TYPE K TC WIRE

- CALIBRATION — K
- WIRE LENGTH — 375 FT
- WIRE AWG — 20
- WIRE INSULATION — GLASS OVER GLASS
- SPECIAL OPTIONS — STAINLESS STEEL OVERBRAID

**OSK3390**  
**\$399/100' Spool**  
 Plus One-Time Set-Up Charge

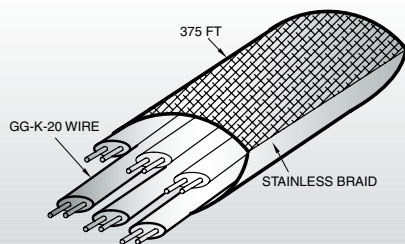

### 36 AWG WIRE WITH OVERALL DIMENSIONS

- CALIBRATION — K
- WIRE AWG — 36
- WIRE INSULATION — PFA ON PFA
- WIRE LENGTH — ANY

**OSK70497**  
**\$65/100' Spool**  
 Plus One-Time Set-Up Charge

