

Four-Range Portable Digital Conductivity Meters

1 YEAR WARRANTY
(Electronics Only)

N

- ✓ Four Ranges, from 200 to 200,000 μS
- ✓ Automatic Temperature Compensation
- ✓ Detachable Electrode

The CDH-80MS is a handheld four-range conductivity meter that can be used to test samples ranging from pure water to seawater. The digital display shows the conductivity of samples; using pushbuttons located on the instrument's handle, switching between the four ranges is easily accomplished. For accuracy of measurement, automatic temperature compensation is provided from 0 to 70°C using a 1000 Ω RTD.

Specifications

Range	Resolution	Accuracy
0 to 200	0.1 μS	$\pm 1\%$ FS
0 to 2,000	1 μS	$\pm 1\%$ FS
0 to 20,000	10 μS	$\pm 1\%$ FS
0 to 200,000	100 μS	$\pm 1.5\%$ FS

Temperature Compensation:

Automatic 0 to 70°C (32 to 158°F)

Power: 9 V battery (included)

Dimensions:

158.8 x 31.8 x 57.2 mm

Weight: 241 g (8.5 oz)

IN STOCK FOR FAST DELIVERY!

To Order (Specify Model Number)

Model No.	Price	Description
CDH-80MS	£279	Conductivity meter 0-200, 0-2,000, 0-20,000, 0-200,000 μS ranges
PHH-60BMS	295	pH/conductivity meter, 0-19,999 μmho , 0-14 pH
PHH-60BTDS	295	pH/conductivity meter, 0-19,999 ppm, 0-14 pH
PHH-80BMS	336	pH/conductivity meter, 0-199,999 μmho , 0-14 pH
PHH-80BTDS	336	pH/conductivity meter, 0-199,999 ppm, 0-14 pH

Accessories and Replacement Electrodes

Model No.	Price	Description
CDE-8002A	£57.00	CDH-80MS replacement stick conductivity sensor
CDE-8036A	58.00	CDH-80MS conductivity sensor with 1 m extension cable
CDE-60	15.50	1 m (3') cable extension for CDE-8002A sensor
PHEC-60B	31.00	1 m (3') pH extension triax cable

Ordering Example: CDH-80MS, four-range conductivity meter, £279




Model CDH-80MS

£279

Shown Smaller Than Actual Size

Each CDH-80MS is supplied with sensor, screwdriver, vinyl carrying case, wire brush, detergent powder, battery and operator's manual.

Dual pH/Conductivity
The Most Popular Pocket Pal® Meter

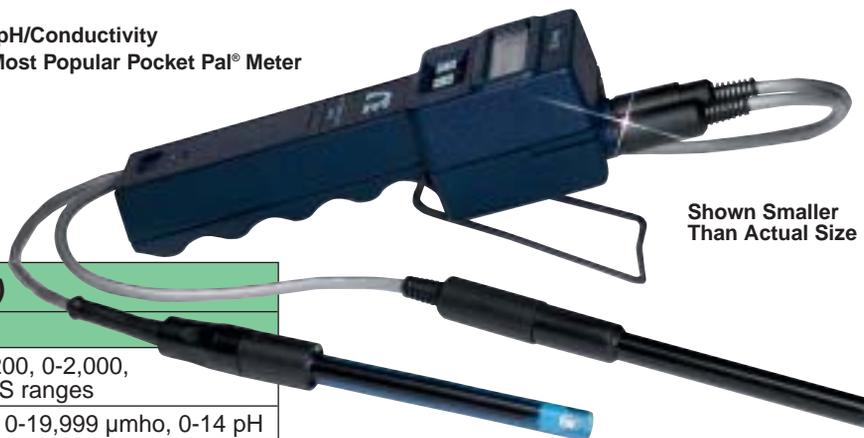

Shown Smaller Than Actual Size

Standard detachable electrodes shown on 1m optional extension cables

PHH-60BMS shown with optional 1m extension cables (stick sensors included)

Calibration Solutions

Model No.	Price	Description
CDS-45	£8.20	45 $\mu\text{mho/cm}$ conductivity solution
CDS-450	8.20	450 $\mu\text{mho/cm}$ conductivity solution
CDS-1500	8.20	1500 $\mu\text{mho/cm}$ conductivity solution
CDS-4500	8.20	4500 $\mu\text{mho/cm}$ conductivity solution

Note: Conformance Certificate available at time of purchase. Add suffix "-NIST" to model number and add £20.50 to price.

Ordering Example: CDH-1500, 1500 $\mu\text{mho/cm}$ conductivity solution, £8.20