

# GENERAL PURPOSE PURGE ROTAMETERS

**CAPACITIES: 0.0046 to 19 GPH of Water, 249 to 1350 cc/min of Water**  
**FL-1300: 0.034 to 85 SCFH of Air**  
**FL-1400: 14.6 to 43,000 cc/min of Air**


FL-1300 Series Starts at

**\$703**



- ✓ ±5% Full Scale Accuracy (FL-1400)
- ✓ ±10% Full Scale Accuracy (FL-1300)
- ✓ ±½% Full Scale Repeatability
- ✓ Integral Flow Controller Standard
- ✓ Compact 65 mm (2.6") Scale for FL-1300 or Large 150 mm (5.9") Scale for FL-1400

FL-1300 Series rotameters are supplied with an easy-to-read 65 mm (2.6") scale. The FL-1400 Series features a large, easy-to-read 150 mm (5.9") scale,

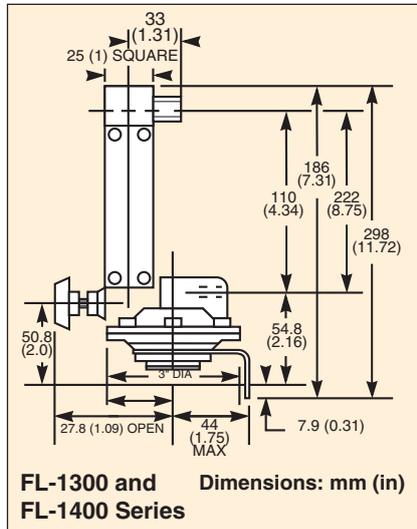

with correlation charts for air and water. The integral flow controller (for both the FL-1300 and FL-1400 Series) maintains a set flow rate when upstream line pressure varies.

Flow controller for varying upstream pressure with constant downstream pressure.

FL-1401, \$763, shown smaller than actual size.



## FL-1300 Series

**MOST POPULAR MODELS HIGHLIGHTED!**

To Order (Specify Model Number)					
Air Model No.	Price	Range (SCFH)	Water Model No.	Price	Range (GPH)
FL-1301	\$703	0.034 to 0.34	FL-1311	\$703	0.0046 to 0.046
FL-1302	703	0.042 to 0.42	FL-1312	703	0.006 to 0.06
FL-1303	703	0.2 to 2.0	FL-1313	703	0.038 to 0.38
FL-1304	703	0.75 to 7.5	FL-1314	703	0.16 to 1.6
FL-1305	703	2.6 to 26	FL-1315	703	0.55 to 5.5
FL-1306	703	8.5 to 85	FL-1316	703	1.9 to 19

For units with brass ends, add suffix "-B" to model number. Price = \$354.

## FL-1400 Series

Model No.	Price	Ranges	
		Air (cc/min)	Water (cc/min)
FL-1401	\$763	14.6 to 146	0.249 to 24.9
FL-1402	763	26.5 to 265	0.493 to 4.93
FL-1403	763	82 to 820	2.06 to 20.6
FL-1404	763	168 to 1680	4.62 to 46.2
FL-1405	763	460 to 4600	13.3 to 133
FL-1406	763	760 to 7600	21.8 to 218
FL-1407	763	1640 to 16,400	49.3 to 493
FL-1408	763	4300 to 43,000	135 to 1350

Comes with complete operator's manual and correlation charts for air and water.

For units with brass ends, add suffix "-B" to model number. Price = \$432.

Ordering Examples: FL-1303, 0.2 to 2.0 SCFH 65 mm scale, \$703.

FL-1405, 460 to 4600 cc/min for air, 13.3 to 133 cc/min for water, 150 mm scale, \$763.

## Accessory

Model No.	Price	Description
FW-0112	\$103	Reference Book: Engineering Fluid Mechanics

B-X

## SPECIFICATIONS

**Metering Tube:** Borosilicate glass

**Float:** 316 stainless steel

**End Fittings:** 316 SS (standard)

Chrome-plated brass (optional)

**O-Rings and Tube Packing:**

FKM (316 SS fittings);

neoprene (brass fittings)

**Max. Pressure:**

13.8 bar (200 psig) up to 121°C (250°F)

**Connections:** Horizontal female ¼ NPT

# omega.co.uk<sup>®</sup>

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

[www.omega.co.uk](http://www.omega.co.uk)



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA

Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)

1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenpfronn, Germany

0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England

0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)

088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)

Karviná, Czech Republic

596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters