

POLYPROPYLENE QUICK-CONNECT HOSE COUPLINGS

FLH Series

\$7

Basic Unit

- ✓ Molded of Glass-Reinforced Polypropylene
- ✓ Nylon Levers
- ✓ Stainless Steel Pins and Rings

- ✓ Rustproof and Resistant to Many Chemicals
- ✓ Retained Gaskets in Couplers Stay in Place When Connections are Open
- ✓ Size Identification Molded into Each Coupling
- ✓ Ideal for Fertilizer, Chemicals, Petroleum, Transport Industry

FEMALE COUPLER (Shown Smaller Than Actual Size) **MOST POPULAR MODELS HIGHLIGHTED!**

NPT MALE THREADS* (BSP optional)



To Order (Specify Model Number)

Model No.	Price	NPT Size
FLHC1F	\$11	1.5
FLHC2F	12	2
FLHC3F	20	3


NPT FEMALE THREADS* (BSP optional)



To Order (Specify Model Number)

Model No.	Price	NPT Size
FLHC7F	\$11	1.5
FLHC8F	12	2
FLHC9F	22	3

HOSE ADAPTOR

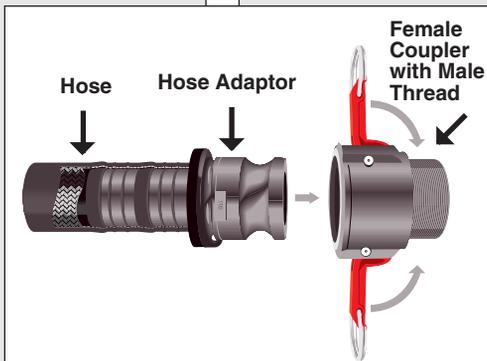

To Order (Specify Model Number)

Model No.	Price	NPT Size
FLHC4F	\$12	1.5
FLHC5F	13	2
FLHC6F	21	3

DUST CAP



To Order (Specify Model Number)

Model No.	Price	NPT Size
FLHC10F	\$12	1.5
FLHC11F	13	2
FLHC12F	20	3

MALE ADAPTOR (Shown Smaller Than Actual Size)

MOST POPULAR MODELS HIGHLIGHTED!

NPT MALE THREADS* (BSP optional)



To Order (Specify Model Number)

Model No.	Price	NPT Size
FLHC7	\$8	1.5
FLHC8	9	2
FLHC9	15	3

DUST PLUG



To Order (Specify Model Number)

Model No.	Price	NPT Size
FLHC10	\$7	1.5
FLHC11	8	2
FLHC12	15	3

NPT FEMALE THREADS* (BSP optional)



To Order (Specify Model Number)

Model No.	Price	NPT Size
FLHC1	\$7	1.5
FLHC2	8	2
FLHC3	12	3

HOSE ADAPTOR



To Order (Specify Model Number)

Model No.	Price	NPT Size
FLHC4	\$8	1.5
FLHC5	9	2
FLHC6	15	3

SPECIFICATIONS

Working pressures:

7 bar (100 psig) @ -18°C (0°F)

8.6 bar (125 psig) @ 21°C (70°F)

4.8 bar (70 psig) @ 66°C (150°F)

and vacuum to 28 inches of mercury.

Hose adaptors have nominal 1 $\frac{3}{16}$ " I.D. and 1 $\frac{7}{16}$ " O.D. barbs.

Max. Shipping Wt: 682 g (1.5 lb)

Ordering Example: FLHC12F, female dust cap with 3 NPT, \$19.

EPDM gasket included with each coupler. If Buna-N is required, add suffix "-BN" to model number (no additional charge); if Vitor® is required, add suffix "-V" to model number and add \$6 for 1 $\frac{1}{2}$ ", \$9 for 2", \$13 for 3 NPT.

* To change NPT to BSP threads, add suffix "-BSP" to model number (no additional charge).

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters