


DIRECT SIDE MOUNTED LEVEL CONTROLS

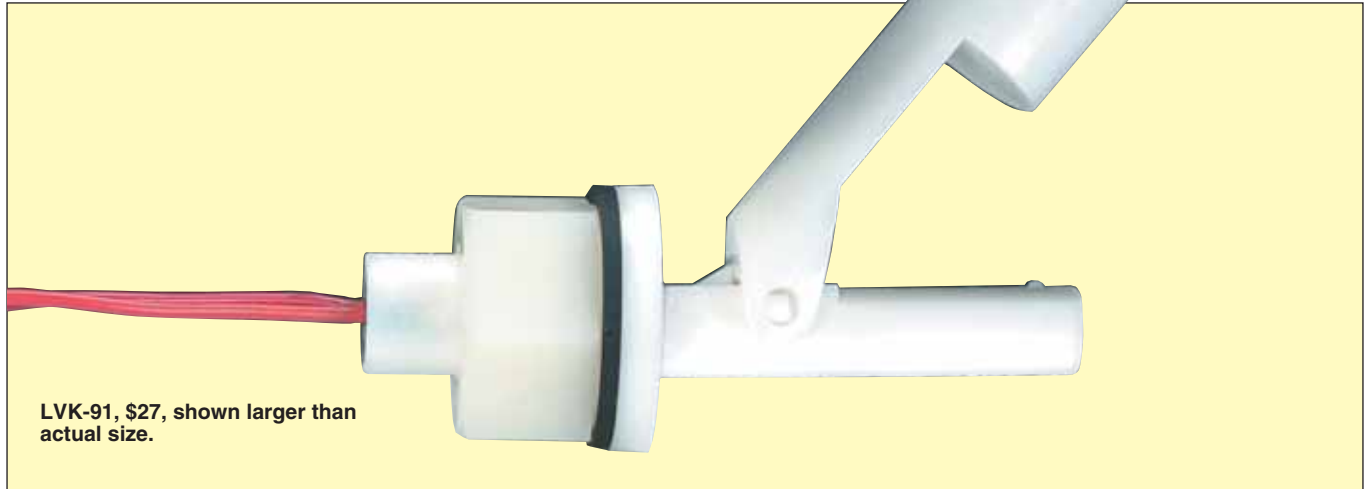


LVK-91, \$27, shown larger than actual size.

LVK-91
\$27

- ✓ Ideal For Tanks With Inaccessible Tops or Bottoms
- ✓ Convenient Side Mounting in Small Tanks
- ✓ Very Compact Size
- ✓ Selectable Normally Open or Normally Closed

The OMEGA® LVK-91 single station horizontal level switch is cost effective for level control applications in small tanks where it is more convenient to install a level switch through the sidewall of the tank. When the float arm is raised to the switch housing, the switch is activated. As the float drops away from the housing, it is deactivated. The movement of the float brings the imbedded magnet into close proximity to the encapsulated reed switch, causing it to actuate. The contact function may be selected as either normally open or normally closed.

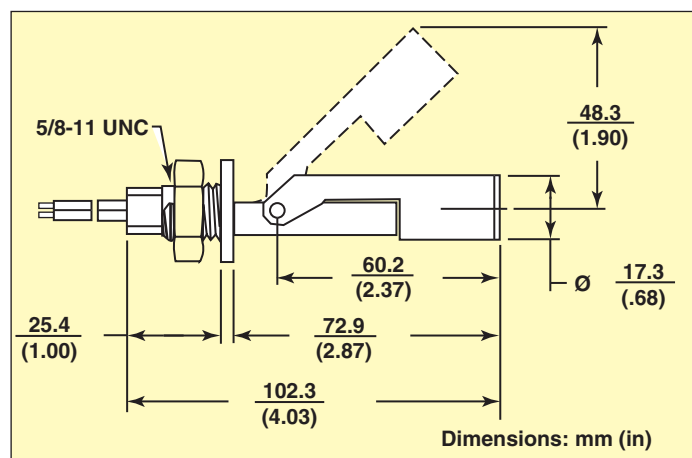

SPECIFICATIONS

Thread: 5/8-11 UNC
 Temperature Range: -40 to 107°C (-40 to 225°F)
 Max. Pressure Rating: 6.89 bar (100 psi) @ 21°C (70°F)

Min. Sp. Gravity Liquid: 0.65
 Switch Rating: 20 VA
 Orientation: Horizontal
 Switch: SPST, reed switch
 Wetted Parts Material: Polybutylene Terephthalate

AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model Number)				
Model No.	Price	Description	Material	Mounting
LVK-91	\$27	Single station horizontal switch	PBT	5/8-11 UNC

Comes with complete operator's manual.
 Ordering Example: LVK-90, 1/2" NPT single station horizontal switch, \$25.

Accessory

Model No.	Price	Description
ES-2208	\$129	Reference Book: Hands On Water And Wastewater Equipment Maintenance Volume II

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters