



Economical pH Testers with Replaceable Electrode

PHH-7X
£28⁵⁰

- ✓ Lightweight and Pocket-Sized
- ✓ Long Battery Life
- ✓ Recommended for Pipes, Tanks and Other Industrial Applications
- ✓ Supplied with Unbreakable pH Electrode

The PHH-7X pH tester provides users with fast, accurate readings on a large, easy-to-read liquid crystal display. It is supplied with an unbreakable epoxy-body pH electrode which screws directly into the lightweight, pocket-sized tester. Despite its ruggedness and simplicity, the PHH-7X provides accurate readings with 0.01 pH resolution.

Ideal for measurements away from the laboratory, the PHH-7X can be used for checking pH samples from pipes, tanks or other industrial applications, and its 3000 hour battery life makes it practical to use in the field for extended periods of time.

SPECIFICATIONS

Range: 0.00 to 14.00 pH

Resolution: 0.01 pH

Accuracy: ±0.2 pH

Calibration: Manual 2 point

Temperature Compensation:
Not Available

Environment: 0 to 50°C
(32 to 122°F), 95% RH


Battery Type / Life: 2 x 1.4V
included, 3000 hours continuous use

Dimensions of electronics:
66 x 50 x 25 mm

Dimensions of electrode:
102mm long, 13mm Dia.

Overall Length: 171.5mm

Weight: Meter 63 g (2.2 oz)

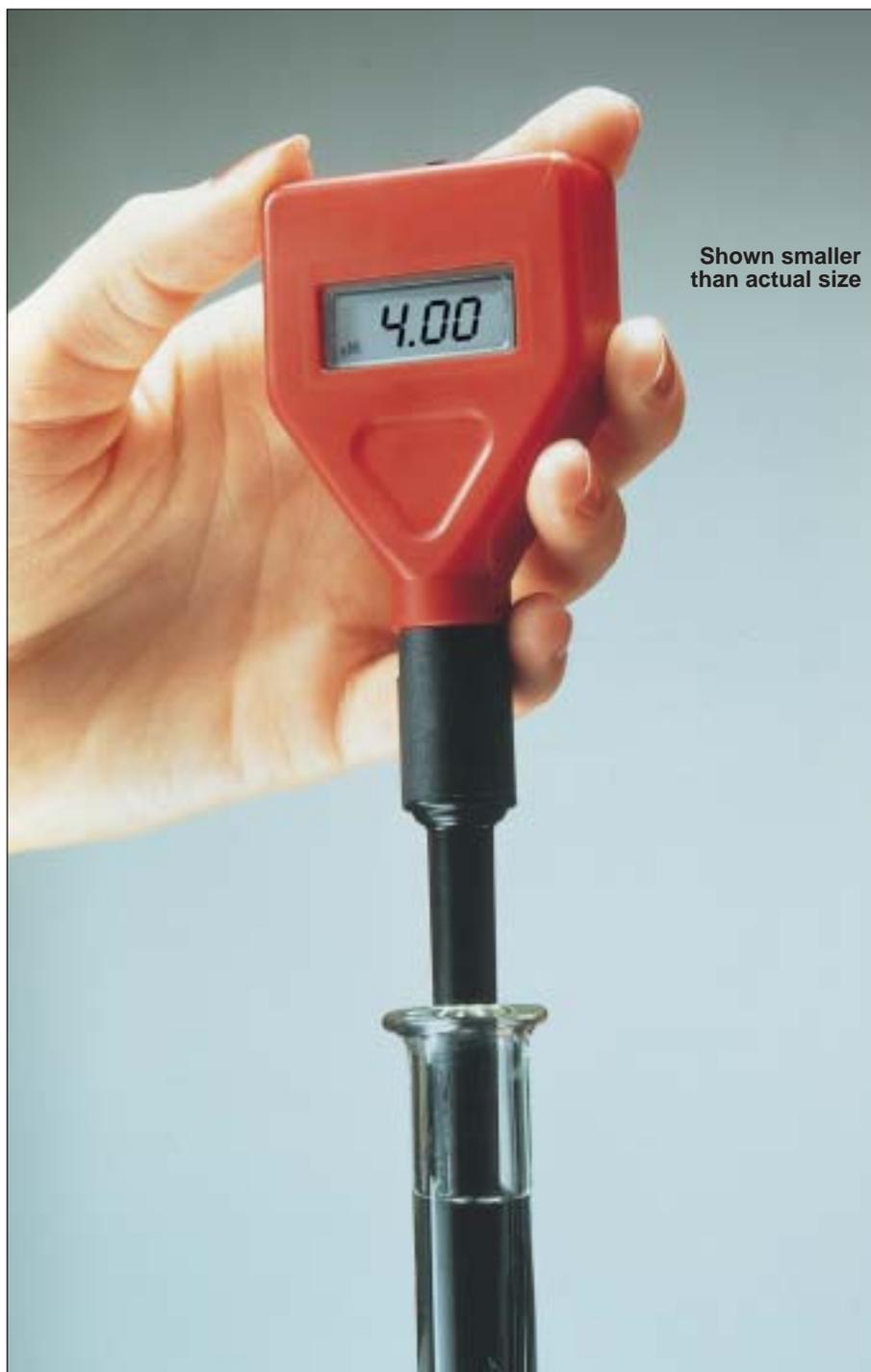

Shown smaller
than actual size

IN STOCK FOR FAST DELIVERY!

To Order (Specify Model Number)		
Model No.	Price	Description
PHH-7X	£28.50	pH Tester with electrode
PHH-7X-R	13.00	Replacement electrode
PH-BATT-3	0.80	Replacement battery (two required)

Comes with batteries and complete operators manual

Ordering Example: PHH-7X, pH Tester with electrode, £28.50