


FLUOROPOLYMER COVERED IMMERSION HEATERS

GTF and GTFL Series
Starts at



\$370

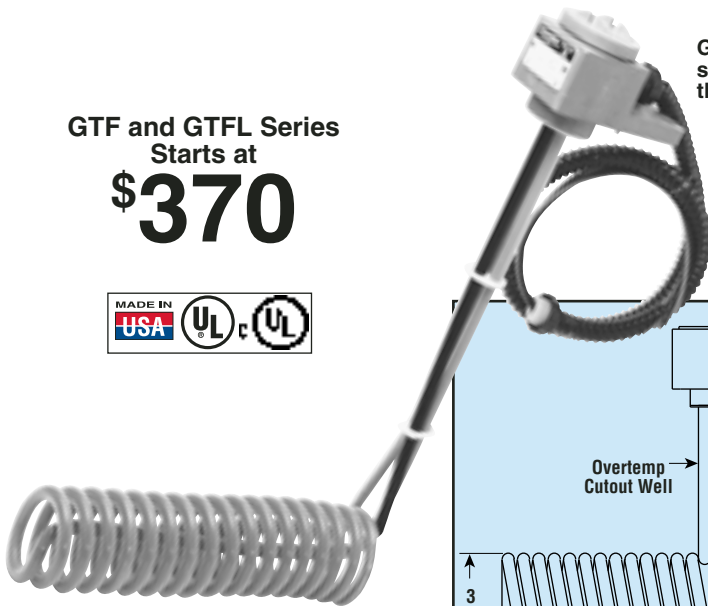

GTFL-11, \$398,
shown smaller
than actual size.



GTF-11, \$370,
shown smaller
than actual size.

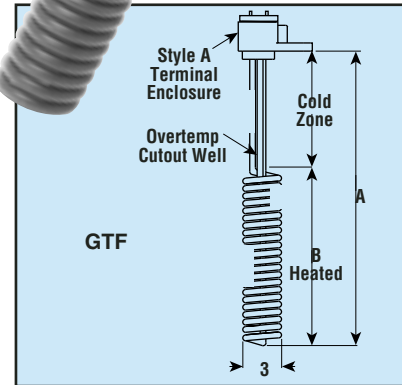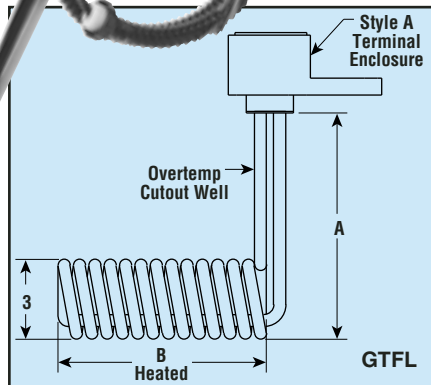

- ✓ GTF—Side Mount
- ✓ GTFL—L-Shaped
- ✓ Fluoropolymer Covered Stainless Steel Elements
- ✓ 10 W/in²
- ✓ 1 to 6 kW
- ✓ 120, 240 and 480V, 1 Phase
- ✓ Moisture Resistant Terminal Enclosure

FEATURES

- ✓ Moisture Resistant Terminal Enclosure
- ✓ Side Mounted Vertical Construction with Mounting Bracket (GTF Only)
- ✓ Side Mounted Horizontal Heater L-Shaped (GTFL Only)
- ✓ Overtemperature Protection One Time Use Thermal Fuse (260°F), Field Replaceable
- ✓ Polypropylene Guard, Order Separately
- ✓ Optional Riser Heights Available (GTFL Only)

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)

kW	Volts	W/in ²	Phase	DIM (in)		Fluoropolymer		(lb)	Guard Model No.	Guard* Price
				A	B	Model No.	Price			
GTF — Side Mount										
1	120	10	1	11	6	GTF-11	\$370	7	GTF-1G	\$103
1	240	10	1	11	6	GTF-12	370	7		
2	240	10	1	17	10	GTF-22	497	8	GTF-2G	109
2	480	10	1	17	10	GTF-24	497	8		
3	240	10	1	23	14	GTF-32	602	13	GTF-3G	119
3	480	10	1	23	14	GTF-34	602	13		
4	240	10	1	29	18	GTF-42	821	15	GTF-4G	125
4	480	10	1	29	18	GTF-44	821	15		
5	240	10	1	35	23	GTF-52	928	18	GTF-5G	132
5	480	10	1	35	23	GTF-54	928	18		
6	240	10	1	40	27	GTF-62	1013	21	GTF-6G	139
6	480	10	1	40	27	GTF-64	1013	21		
GTFL — L-Shaped										
1	120	10	1	12	9	GTFL-11	\$398	8	GTFL-1G	\$110
1	240	10	1	12	9	GTFL-12	398	8		
2	240	10	1	18	13	GTFL-22	521	9	GTFL-2G	132
2	480	10	1	18	13	GTFL-24	521	9		
3	240	10	1	18	17	GTFL-32	628	13	GTFL-3G	136
3	480	10	1	18	17	GTFL-34	628	13		
4	240	10	1	18	21	GTFL-42	848	16	GTFL-4G	143
4	480	10	1	18	21	GTFL-44	848	16		
5	240	10	1	18	25	GTFL-52	957	18	GTFL-5G	164
5	480	10	1	18	25	GTFL-54	957	18		
6	240	10	1	18	29	GTFL-62	1039	21	GTFL-6G	179
6	480	10	1	18	29	GTFL-64	1039	21		

* Guard (not shown). Order separately by PN. Guard adds approximately 1/2" to overall heater dimensions.

Ordering Examples: GTF-62, 240V, 6 kW, side mount immersion heater, \$1013 and GTF-6G, heater guard, \$139, \$1013 + 139 = \$1178. GTFL-11, 120V, 1 kW, L-shaped immersion heater, and GTFL-1G, heater guard, \$398 + 110 = \$508.

omega.co.uk®

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

FRANCE

www.omega.fr

0800-466-342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers, Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters