

MEDIUM TEMPERATURE HEATING TAPES

SRT Series
Starts at
£33

- ✓ Maximum Exposure Temperature up to 230°C
- ✓ Uniform Heat Distribution
- ✓ Moisture and Chemical Resistant
- ✓ Available with Leads Same End†

OMEGALUX™ Silicone Rubber Extruded Heating Tapes are low-watt density electrical resistance heaters designed for temperature maintenance in applications requiring moisture and chemical resistance. Silicone rubber tapes are constructed of finely stranded resistance wires fully insulated with braided fibreglass and knitted into flat tape with fibreglass yarn. These tapes are encapsulated in a void-free silicone rubber sheath.

SPECIFICATIONS

Heating Elements: 36-40 gauge finely stranded resistance wire


Heating Elements Insulation: double braided fibreglass yarn

Dielectric Strength: in excess of 2000V

Lead Wires: 16 AWG high temperature 600V silicone rubber insulated lead wire emerging from opposite ends of the heating tape

APPLICATIONS

- ✓ Silicone rubber extruded heating tapes can be used in direct contact with a metal or conductive surface

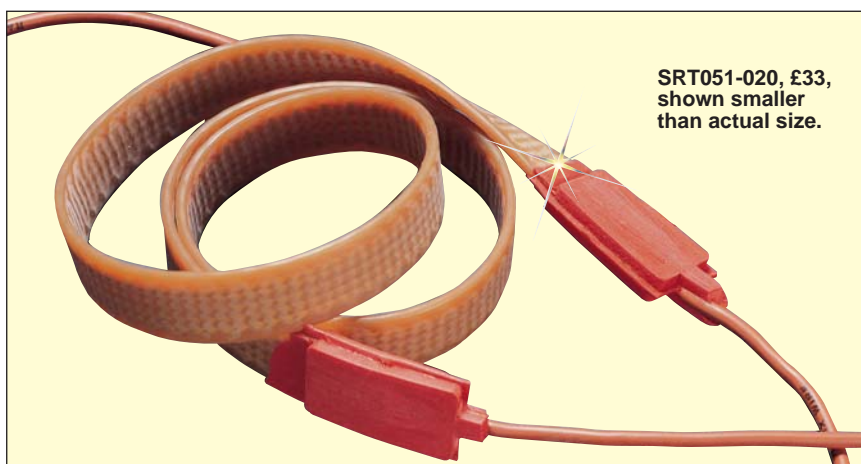

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)					
Watts	W/in ²	Volts	Size cm/m	Model No.	Price
52	4.3	120	1/0.6	SRT051-020	£33
104	4.3	120	1/1.2	SRT051-040	37
156	4.3	120	1/1.8	SRT051-060	44
209	4.3	120	1/2.4	SRT051-080	52
261	4.3	120	1/3	SRT051-100	59
313	4.3	120	1/3.7	SRT051-120	53
104	4.3	120	2.5/0.6	SRT101-020	44
209	4.3	120	2.5/1.2	SRT101-040	55
313	4.3	120	2.5/1.8	SRT101-060	70
418	4.3	120	2.5/2.4	SRT101-080	80
522	4.3	120	2.5/3	SRT101-100	92
627	4.3	120	2.5/3.7	SRT101-120	98
731	4.3	120	2.5/4.3	SRT101-140	113
836	4.3	120	2.5/4.9	SRT101-160	121
940	4.3	120	2.5/5.	SRT101-180	132
1045	4.3	120	2.5/6.	SRT101-200	143
209	4.3	120	5/0.6	SRT201-020	59
418	4.3	120	5/1.2	SRT201-040	84
627	4.3	120	5/1.8	SRT201-060	117
836	4.3	120	5/2.4	SRT201-080	147
1045	4.3	120	5/3	SRT201-100	161
1254	4.3	120	5/3.7	SRT201-120	176
1463	4.3	120	5/4.3	SRT201-140	187
1672	4.3	120	5/4.9	SRT201-160	212
1881	4.3	120	5/5.5	SRT201-180	242
2090	4.3	120	5/6.1	SRT201-200	260

† To order heaters with power leads exiting the same end of the tape, add suffix “-LSE” to model number. Call Sales for pricing. To order 240V version change the “1” before the “-” in model number to “2”. Call Sales for prices.

Comes with instruction sheet.

Ordering Example: SRT052-240, 240V, 156 Watt, heating tape, £44.



UNITED STATES

www.omega.com

1-800-TC-OMEGA

Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)

1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany

0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England

0800-488-488

FRANCE

www.omega.fr

088-466-342

CZECH REPUBLIC

www.omegaeng.cz

Karviná, Czech Republic

596-311-899

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters