 


PRECISION STRAIN GAGE



PRE-WIRED STRAIN GAGES





MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)

ENCAPSULATED WITH 2 LEAD WIRES, 1 M (3') LONG, ATTACHED

MODEL NO.	PRICE PER PKG OF 10	NOM. RESISTANCE (Ω)	DIMENSIONS mm (in) [†]				MAX V (Vrms)	TERMINATION	TEMP COMP.	FIG.
			GRID		CARRIER					
			A	B	C	D				
KFG-02-120-C1-11 L1 M2R	\$140	120	0.2 (0.008)	1.3 (0.051)	3.3 (0.13)	2.4 (0.094)	1	2 wire	STE	1
KFG-1N-120-C1-11L1M2R	109	120	1.0 (0.039)	0.7 (0.028)	4.2 (0.17)	1.4 (0.055)	1.5	2 wire	STE	2
KFG-2N-120-C1-11L1M2R	94	120	2.0 (0.079)	0.9 (0.035)	5.3 (0.21)	1.4 (0.055)	2	2 wire	STE	2
KFG-3-120-C1-11L1M2R	88	120	3.0 (0.12)	1.3 (0.051)	7.4 (0.29)	2.8 (0.11)	4	2 wire	STE	3
KFG-3-350-C1-11L1M2R	121	350	3.0 (0.12)	1.3 (0.051)	7.4 (0.29)	2.8 (0.11)	15	2 wire	STE	3
KFG-5-120-C1-11L1M2R	80	120	5.0 (0.2)	1.4 (0.055)	9.4 (0.37)	2.8 (0.11)	8	2 wire	STE	3
KFG-5-350-C1-11L1M2R	124	350	5.0 (0.2)	1.4 (0.055)	9.4 (0.37)	2.8 (0.11)	20	2 wire	STE	4
KFG-10-120-C1-11L1M2R	100	120	10.0 (0.39)	3.0 (0.12)	16.0 (0.63)	5.2 (0.2)	15	2 wire	STE	4
KFG-30-120-C1-11 L1M2R	119	120	30.0 (1.18)	3.3 (0.13)	37.0 (1.46)	5.2 (0.2)	25	2 wire	STE	5

See ordering chart above

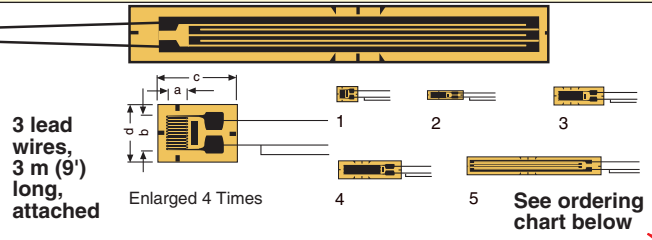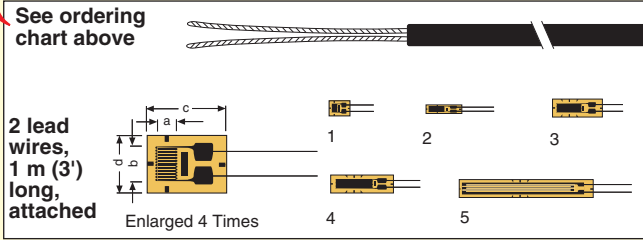

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)

ENCAPSULATED WITH 3 LEAD WIRES, 3 M (9') LONG, ATTACHED

MODEL NO.	PRICE PER PKG OF 10	NOM. RESISTANCE (Ω)	DIMENSIONS mm (in) [†]				MAX V (Vrms)	TERMINATION	TEMP COMP.	FIG.
			GRID		CARRIER					
			A	B	C	D				
KFG-02-120-C1-11L3M3R	\$184	120	0.2 (0.008)	1.3 (0.051)	3.3 (0.13)	2.4 (0.094)	1	3 wire	STE	1
KFG-1N-120-C1-11L3M3R	153	120	1.0 (0.039)	0.7 (0.028)	4.2 (0.17)	1.4 (0.055)	1.5	3 wire	STE	2
KFG-2N-120-C1-11L3M3R	138	120	2.0 (0.079)	0.9 (0.035)	5.3 (0.21)	1.4 (0.055)	2	3 wire	STE	2
KFG-3-120-C1-11L3M3R	131	120	3.0 (0.12)	1.3 (0.051)	7.4 (0.29)	2.8 (0.11)	4	3 wire	STE	3
KFG-3-350-C1-11L3M3R	165	350	3.0 (0.12)	1.3 (0.051)	7.4 (0.29)	2.8 (0.11)	15	3 wire	STE	3
KFG-5-120-C1-11L3M3R	124	120	5.0 (0.2)	1.4 (0.055)	9.4 (0.37)	2.8 (0.11)	8	3 wire	STE	3
KFG-5-350-C1-11L3M3R	165	350	5.0 (0.2)	1.4 (0.055)	9.4 (0.37)	2.8 (0.11)	20	3 wire	STE	4
KFG-10-120-C1-11L3M3R	145	120	10.0 (0.39)	3.0 (0.12)	16.0 (0.63)	5.2 (0.2)	15	3 wire	STE	4
KFG-30-120-C1-11L3M3R	163	120	30.0 (1.18)	3.3 (0.13)	37.0 (1.46)	5.2 (0.2)	25	3 wire	STE	5

DISCOUNT SCHEDULE

1 to 10 pkgsNet
11 to 24 pkgs5%
25 to 49 pkgs10%
50 and up and OEMConsult Factory

[†] For dimensions key, see page 15. **Note:** For strain gage accessories see pages 59 to 61.
Ordering Example: KFG-02-120-C1-11L1M2R, package of 10 pre-wired strain gages, encapsulated with 2 lead wires attached, \$140.

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

FRANCE

www.omega.fr

0800-466-342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters