

# 483 mm (19") Jack Panels

## 3-Prong Connectors with Anodized Panels

### Rugged 3.2 mm (1/8") Thick Panels

ANSI color code shown To order IEC color code see page A-9



19TJP Series Starts at **\$75**

#### 483 mm (19") Plain Panel Jacks


No. of Rows	Panel Height	Max No. of Jacks
1	89 mm (3½")	22
2	133 mm (5¼")	44
3	222 mm (8¾")	66
4	267 mm (10½")	88

#### 483 mm (19") Panel Jacks with Switch Cutout

No. of Rows	Panel Height	Switch Size	Max No. of Jacks
1	127 mm (7")	76 mm (5")	15
2	127 mm (7")	76 mm (5")	30
3	222 mm (8¾")	76 mm (5")	45
4	267 mm (10½")	76 mm (5")	60

**Note:** When a switch is ordered with a panel, installation is included at no extra cost.

SW142 Series, \$125, see page G-68

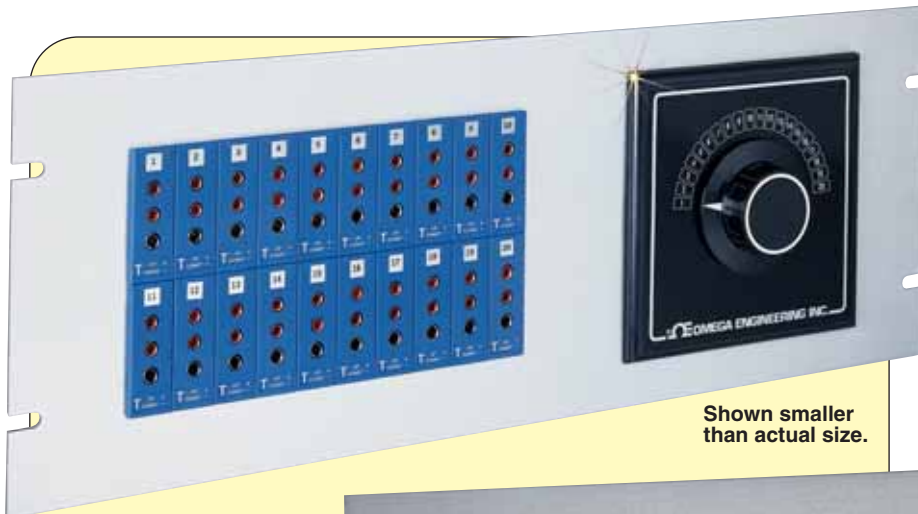

Shown smaller than actual size.

Switches and Meter Sold Separately



DP41B, \$595, see page M-27.

**MOST POPULAR MODELS HIGHLIGHTED!**

Model No. ANSI Color Code	Price	Total No. of Jacks	Switch Cutout	Meter Cutout
19TJP1-10-(*)	\$75	10	-	-
19TJP1-20-(*)	106	20	-	-
19TJP2-20-(*)	116	20	-	-
19TJP2-30-(*)	150	30	-	-
19TJP2-40-(*)	188	40	-	-
19TJP1-10-(*)-OSW	85	10	76 mm (5")	-
19TJP2-20-(*)-OSW	121	20	76 mm (5")	-
19TJP3-30-(*)-OSW	160	30	76 mm (5")	-
19TJP4-40-(*)-OSW	203	40	76 mm (5")	-
19TJP1-10-(*)-OSW-MTR	90	10	76 mm (5")	y
19TJP2-20-(*)-OSW-MTR	126	20	76 mm (5")	y
19TJP3-30-(*)-OSW-MTR	165	30	76 mm (5")	y
19TJP4-40-(*)-OSW-MTR	238	40	76 mm (5")	y

Panels with switches and/or meters do not come supplied wired. Wiring charge is \$5 per circuit. Consult factory for details.

#### 483 mm (19") Jack Panels with Switch and Meter Cutouts

No. of Rows	Panel Height	Switch Size	Max. No. of Jacks
1	127 mm (7")	76 mm (5")	10
2	127 mm (7")	76 mm (5")	20
3	222 mm (8¾")	76 mm (5")	30
4	267 mm (10½")	76 mm (5")	40

**Note:** A 45 x 92 mm (1 7/8" DIN) meter cutout is supplied unless otherwise specified.

Consult Sales Department for information on custom, color-coded anodized panels.

\* Insert calibration code in model number

Ordering Example: 19TJP4-40-K-OSW, 483 mm (19") jack panel with Type K connector, \$203.



#### UNITED STATES

[www.omega.com](http://www.omega.com)  
1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)  
Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)  
Deckenpfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)  
Manchester, England  
0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)  
Guyancourt, France  
088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)  
Karviná, Czech Republic  
596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)  
Amstelveen, NL  
0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters