

# Fabricated Thermowells

Starts at  
**£25**

**CUSTOM  
ENGINEERING**  
TELL US WHAT YOU  
NEED AND WE'LL MAKE IT



- ✓ 316 Stainless Steel
- ✓ R1/2 (1/2" BSPT) Process Connection
- ✓ 11mm O.D Tube with 7mm I.D for 6mm or 1/4" dia Probes
- ✓ G1/4 (1/4" BSPP) Female Thread for Probe Connection

OMEGA's range of stainless steel welded construction thermowells are designed for use with our 6mm and 1/4" diameter thermocouple or PT100 sensors.

They are ideally suited to applications where the sensor may need to be removed without affecting the process, such as in pipes and tanks.


## To Order *(Specify Model Number)*

**AVAILABLE FOR FAST DELIVERY!**

Part No.	Insertion length	Sensor length	Price
FTW-G4-11-80-R2	80	150	£25
FTW-G4-11-230-R2	230	300	£30
FTW-G4-11-380-R2	380	450	£35
FTW-G4-11-530-R2	530	600	£40

## Accessories

Part No.	Description	Price
SSLK-M60-14P	SS Compression Gland for 6mm probe	£15.50
BRLK-14-14P	Brass Compression Gland for 6mm probe	£8.00

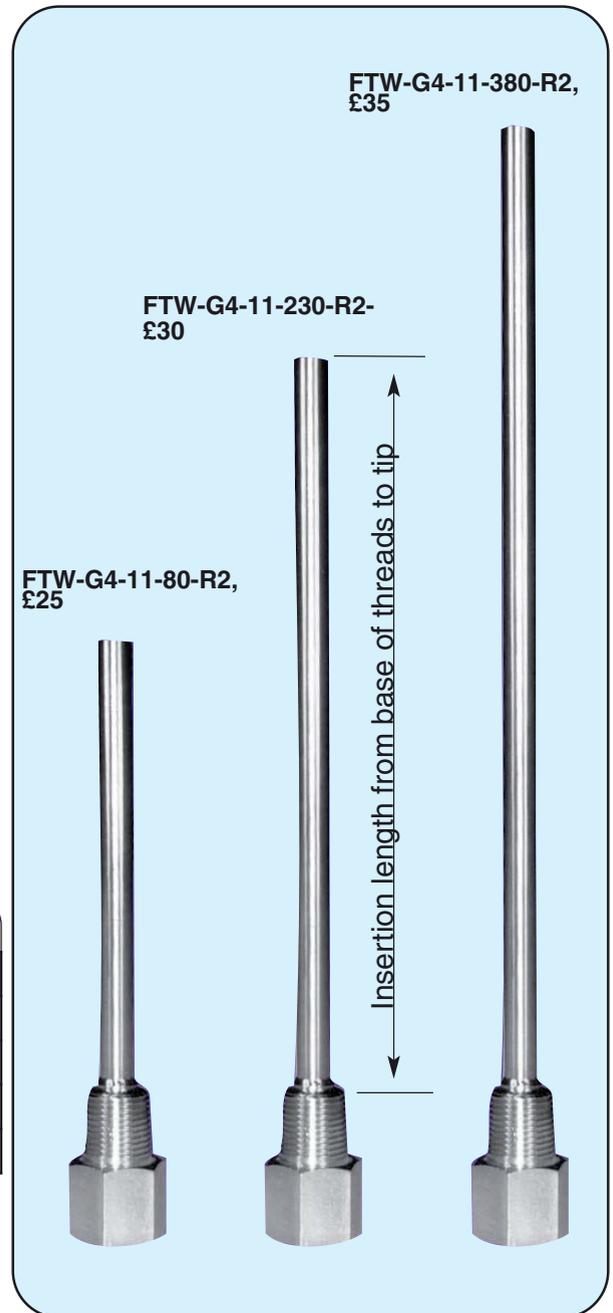

All shown smaller than actual size

**Ordering Example :** FTW-G4-11-230-R2, Fabricated Thermowell with 230mm insertion length and 1/2" BSPT process fitting, £30.

Contact Sales for non-standard lengths, diameters, materials and fittings.

# omega.co.uk<sup>®</sup>

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

[www.omega.co.uk](http://www.omega.co.uk)



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England  
0800-488-488  
+44-(0)161-777-6611

#### FRANCE

[www.omega.fr](http://www.omega.fr)

0800-466-342

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters