


# Accessories for Glass Thermometers

GTA Series  
Starts at  
**\$9**

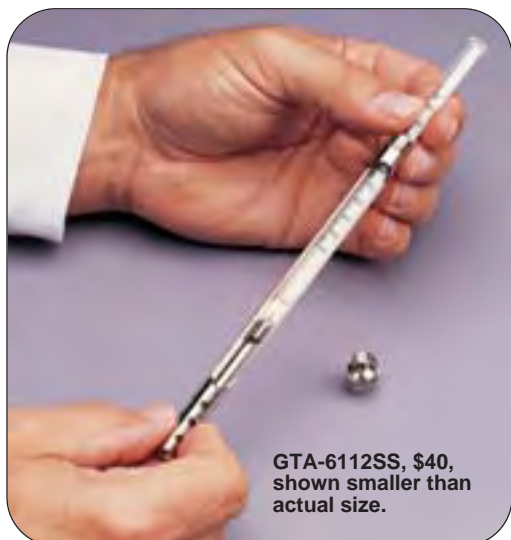

GTA-6112SS, \$40, shown smaller than actual size.

## Open Face Armor Case

OMEGA® glass thermometers can be armored for added protection. The open face case is 2<sup>3</sup>/<sub>4</sub>" diameter and made of attractive, durable plated brass. The lower end is perforated to permit free heat passage. The face is open so the protected thermometer can be read without removing it from the case. Stainless steel sheaths are also available in 305 mm (12") and 406 mm (16") lengths.


**MOST POPULAR MODELS HIGHLIGHTED!**

### To Order (Specify Model Number)

Model No.	Price	Length mm (in)	Material
GTA-6106BR	\$9	152 (6)	Brass
GTA-6109BR	12	229 (9)	Brass
GTA-6110BR	12	254 (10)	Brass
GTA-6112BR	12	305 (12)	Brass
GTA-6112SS	40	305 (12)	Stainless
GTA-6114BR	15	356 (14)	Brass
GTA-6115BR	16	381 (15)	Brass
GTA-6116BR	16	406 (16)	Brass
GTA-6116SS	48	406 (16)	Stainless
GTA-6118BR	19	457 (18)	Brass
GTA-6120BR	27	508 (20)	Brass
GTA-6124BR	34	610 (24)	Brass

Ordering Example: GTA-6112SS, 305 mm (12") stainless steel sheath, \$40.

GTM Series  
Starts at  
**\$13**

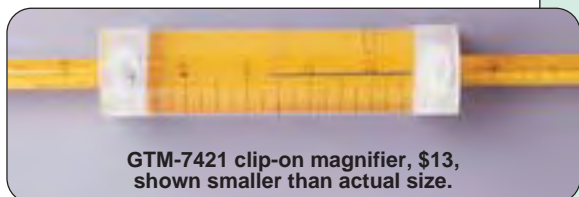

GTM-7421 clip-on magnifier, \$13, shown smaller than actual size.



GTM-7425 hand lens with case, \$45, shown smaller than actual size.

## Magnifiers

Two types of magnifiers are available: a reading lens that clips onto the thermometer and a hand lens. The 3" plastic magnifier clips directly onto the thermometer and provides a useful reading aid. The handheld lens is 2<sup>1</sup>/<sub>4</sub>" long by 1" in diameter. The focal length is 3", field diameter is 3/4", magnification is 6x. This lens is excellent for estimating intergraduations.

**MOST POPULAR MODELS HIGHLIGHTED!**

### To Order (Specify Model Number)

Model No.	Price	Description
GTM-7421	\$13	Clip-on magnifier lens
GTM-7425	45	Hand lens with case

Ordering Example: GTM-7421, clip-on magnifier lens, \$13.

# omega.co.uk<sup>®</sup>

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

[www.omega.co.uk](http://www.omega.co.uk)



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA  
Stamford, CT.

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England  
0800-488-488  
+44-(0)161-777-6611

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)  
1-800-TC-OMEGA

#### FRANCE

[www.omega.fr](http://www.omega.fr)

0800-466-342

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenfronn, Germany  
0800-8266342

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters