

Digital Thermometers

Starts at
£50

- ✓ J, K, T, E, R, S, N Thermocouple and Pt3926 and Pt385 RTD Input Types
- ✓ Provides Max/Min, Avg, Hold, Relative
- ✓ Warning Beeper with Hi/Lo Setting, Time Setting on models HH502 through HH509
- ✓ Dual Display Function
- ✓ 0.1° Resolution
- ✓ Differential Thermocouple Input
- ✓ Accuracy: Stated Accuracy at 23 ± 5°C <75% RH
- ✓ Battery Life: 200 Hours
- ✓ Dimensions: 192 H x 91 W x 53 mm D (7.6 x 3.6 x 2.2")
- ✓ Weight: Approx 255 g (9 oz)
- ✓ Water/Splash Resistant

New Model!
HH501A Now Accepts Type J or K Thermocouple Inputs!



New Model!
HH501B Now Accepts Type J or K Thermocouple Inputs!



All Thermocouple and RTD Probes Sold Separately. See Sections A and C for More Details!

Thermocouple Included!

Thermocouple models include a free 1 m Type K or appropriate alternative beaded wire thermocouple with subminiature connector and wire spool caddy (1 per channel).
Order a Spare! Model No. SC-GG-KI-30-1M, £10.

All K Type Models Supplied with Yellow Rubber Boot; All Others Are Black.



Comes with protective rubber boot with tilt stand, 9 V alkaline battery and complete operator's manual. Temperature models include 1 or 2 beaded wire thermocouples (1 per channel).

Handheld Digital Thermometers

HH506A
£90



HH506A Dual K/J/E/T/R/S/N Input
19999 counts, Backlit LCD display
Measures Type K, J, E, T, R, S, N thermocouples; Max/Min, Avg, Rel, Hold function; Dual input function T1/T2

HH508
£74
Single Input

HH509
£80
Dual Input

HH509R
£87
RS232



HH508 Single, HH509 Dual K/J/E/T/S Input
1999 counts, Backlit LCD display; Measures Type K, J, E, T, S thermocouples; Max/Min, Avg, Rel, Hold function

All Thermocouple and RTD Probes Sold Separately. See Sections A and C for More Details!

HH505
£50



HH505 Pt3926/385 RTD Thermometer
20000 counts resolution
Measures Pt3926/385 RTD standard Max/Min, Avg, Rel, Hold function single input function
TS-90 accuracy: $\pm 0.05\%$
Includes male RTD input mating connector (MTP-U-M)

RS232 Interface and Data Logging.




HH506RA
£97
Dual Input

HH506RA Dual K/J/E/T/R/S/N Input with RS232 and logging ability
19999 counts, Backlit LCD display
Measures Type K, J, E, T, R, S, N thermocouples; Max/Min, Avg, Rel, Hold function; Dual input function T1/T2
Includes RS232 cable and software

Combination Contact and Non-Contact (IR) Food Service Model with Type K Input.

OS643W
£90
°C/°F
Switchable with Type K Thermocouple Input

OS643W
Switchable from IR to T/C
Temperature Range:
IR: 0 to 500°F
T/C: -58 to 2000°F
Accuracy:
IR: $\pm 3\%$ rdg
T/C: $\pm 0.3\%$ rdg + 2°F
Analog Output: 1 mV/°C/°F
Emissivity: 0.95
Detection Element: Thermopile
Comes with beaded wire Type K thermocouple.

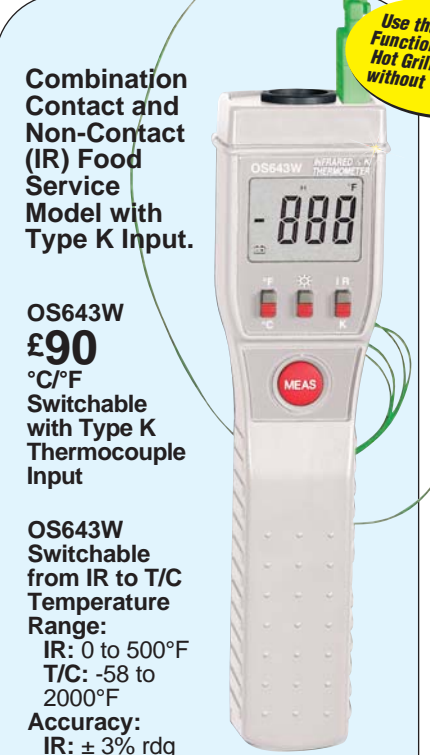

Use the Infrared Function to Check Hot Grill Surfaces without Touching!

HH63K
£54



HH63K Stick Type Thermometer
3½ digits 2000 counts; Reading of Max, Data Hold, function overload protection
24 Vac/Vdc; Accuracy up to $\pm 0.3\%$; °C/°F switchable
Comes with beaded wire Type K thermocouple.

Comes with protective rubber boot with tilt stand, 9 V alkaline battery and complete operator's manual. Temperature models include 1 or 2 beaded wire thermocouples (1 per channel).



UNITED STATES

www.omega.com

1-800-TC-OMEGA

Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)

1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany

0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England

0800-488-488

FRANCE

www.omega.fr

088-466-342

CZECH REPUBLIC

www.omegaeng.cz

Karviná, Czech Republic

596-311-899

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters