

Flexible Sealed PFA RTD Sensors

For Use in Corrosive Environments and Tight Places




RTDS

HSRTD Series
Starts at
£30



OMEGACAL™
Factory CAL
AVAILABLE
omega.co.uk

- ✓ 100 , Class "A" DIN Platinum Element Standard, Other Resistances and Classes Available
- ✓ Sealed Against Moisture and Corrosion
- ✓ PFA Insulated Cable (Colour Coded Per IEC751/ASTM-E-1137)
- ✓ Temperature Range: -60 to 260°C
- ✓ 4-Wire Configuration Standard

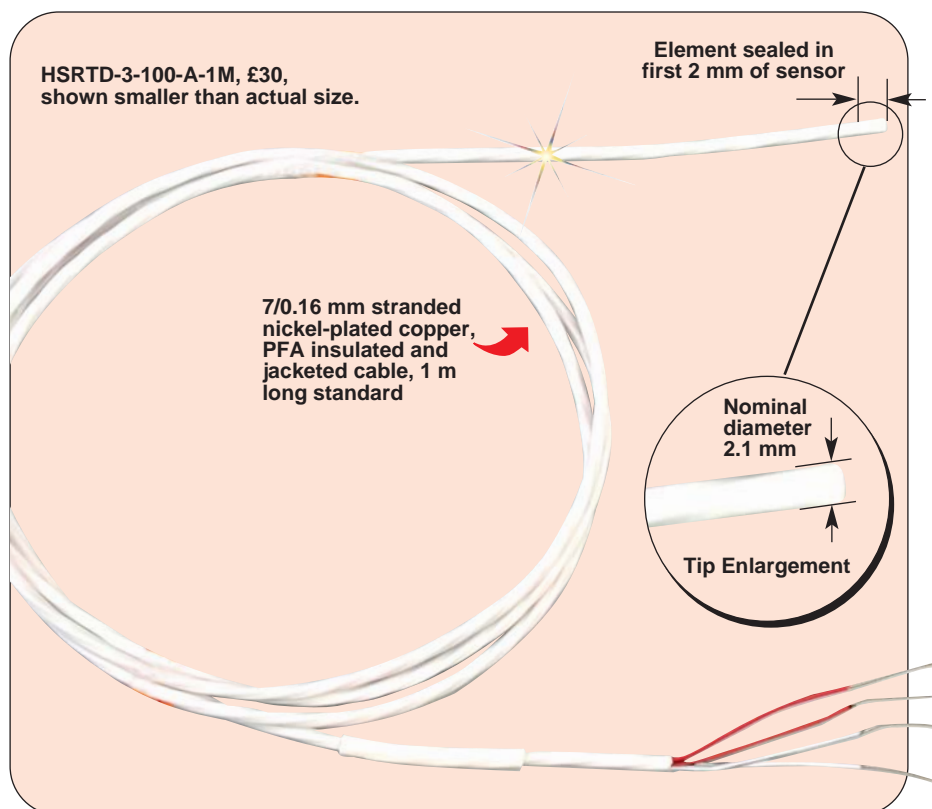

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)


Model Number	Resistance	Number of Wires	Wire Length	Price
HSRTD-3-100-A-1M	100 , Class "A"	4	1 m	£30
HSRTD-3-1000-A-1M	1000 , Class "A"	4	1 m	30

Options: For cable lengths greater than 1 m, change "-1M" to required length in metres and add £2 per metre to price. Sensors come with stripped leads standard. For a 4-wire mini DIN connector, add "-MDIN4" to model number and add £8 to price.

Ordering Examples: HSRTD-3-100-A-1M-MDIN4, 100 Class "A" sensor with 1 m of cable and mini DIN connector, £30 + 8 = £38.
HSRTD-3-100-A-3M, 100 Class "A" sensor with 3 m of cable, £30 + (2 x 2) = £34.




Mini DIN Connector,
£8, Fitted. Add "-MDIN4"
to model number.

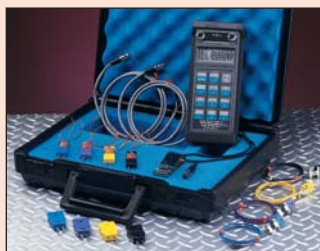

CL27 High Precision Handheld
Calibrator/Thermometer, £705.
See omega.co.uk



OM-CP-QUADRTD
Data Logger £401.
See page 466.

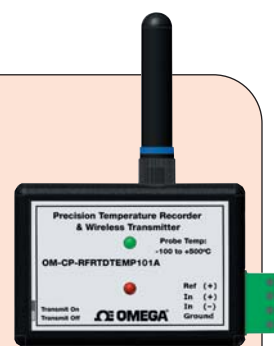

OM-CP-RFRTDTEMP101A
Wireless Transmitter, £301.
See omega.co.uk

omega.co.uk®

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA

Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)

1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany

0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England

0800-488-488

FRANCE

www.omega.fr

088-466-342

CZECH REPUBLIC

www.omegaeng.cz

Karviná, Czech Republic

596-311-899

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters