


Ready-Made Insulated Thermocouples

Hermetically Sealed Tip Design with Stripped Leads




HSTC Series
Start at
£16⁷⁵

- ✓ IP68 Seal-Welded Tip
- ✓ Highly Resilient to Chemicals and Oils
- ✓ Electrically-Insulated Junction
- ✓ Easily Cleaned and Sterilised
- ✓ Small Size Provides a Fast Response
- ✓ Rated to 250°C (482°F)
- ✓ 7/0.2 mm Stranded Thermocouple Wire
- ✓ 1.6 mm x 2.6 mm Nominal Cross Section

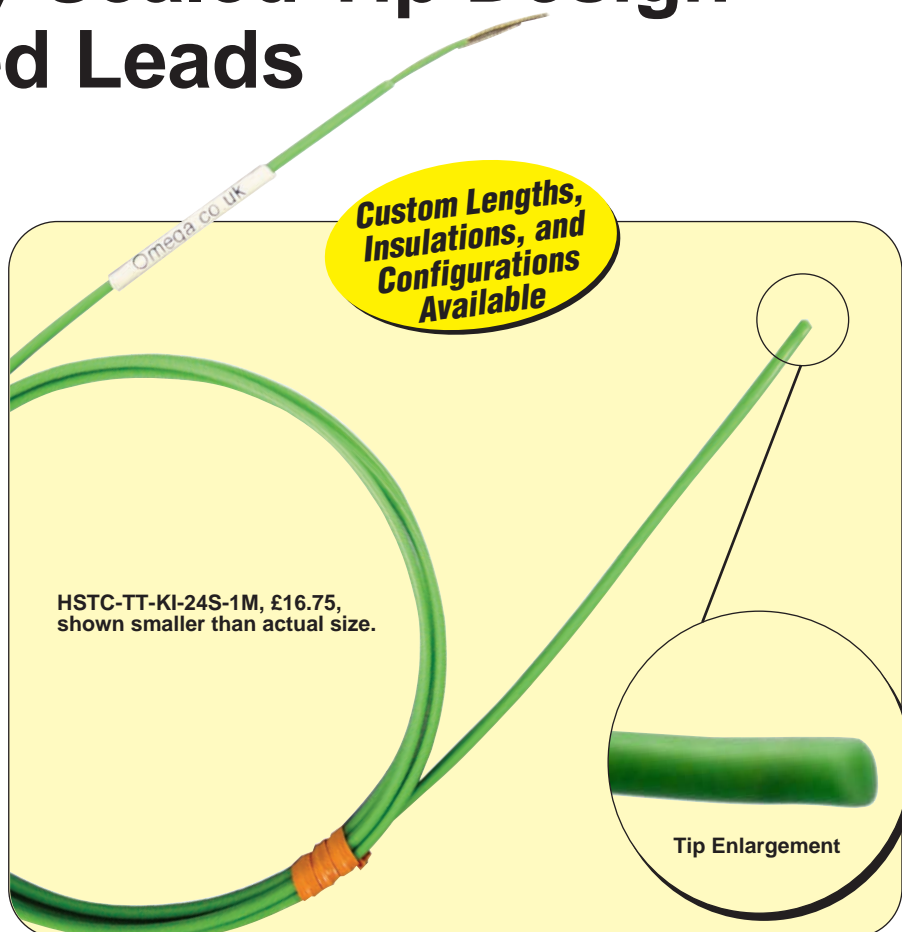

These PFA insulated thermocouple wire sensors are hermetically seal-welded at the sensor tip to provide continuous PFA protection over the measurement junction. This unique design provides a small, flexible, and electrically isolated thermocouple, suited to a variety of applications.

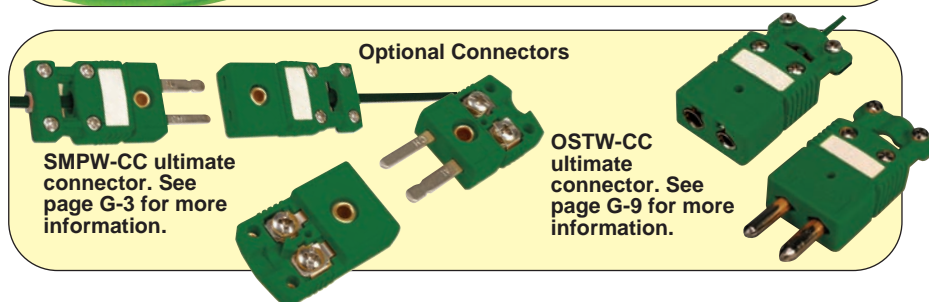

 MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)

Model No.	Price	Description
HSTC-TT-(*)I-24S-1M	£16.75	Hermetically sealed tip thermocouple, 1 m (40"), stripped ends
HSTC-TT-(*)I-24S-2M	18.75	Hermetically sealed tip thermocouple, 2 m (80"), stripped ends
HSTC-TT-(*)I-24S-3M	21.50	Hermetically sealed tip thermocouple, 3 m (120"), stripped ends
HSTC-TT-(*)I-24S-1M-SMPW-CC	20.00	Hermetically sealed thermocouple, 1 m (40"), ultimate SMPW male with cable clamp
HSTC-TT-(*)I-24S-2M-SMPW-CC	22.00	Hermetically sealed thermocouple, 2 m (80"), ultimate SMPW male with cable clamp
HSTC-TT-(*)I-24S-3M-SMPW-CC	24.75	Hermetically sealed thermocouple, 3 m (120"), ultimate SMPW male with cable clamp

* Insert calibration J, K, T, or E.

Add £2 per additional metre of TT wire. To order thermocouple with standard size connector, replace "SMPW" in the model number with "OSTW", no additional charge.

Ordering Example: HSTC-TT-KI-24S-2M-SMPW-CC, 1 each, PFA insulated thermocouple, Type K calibration (CHROMEGA®-ALOMEGA®), 2 metres long, ultimate mini male connector with strain relief, £22.