



# M12 Cables with Field Mountable Connectors for Resistance Sensors (RTDs)

## For Field Adaptable and Special Requirements

- ✓ Straight and Right Angled M12 Field Mountable Connector Sensor End
- ✓ Two Cable Insulations Available
- ✓ 4-Wire Construction, Field Re-Wireable
- ✓ Optional Stainless Steel Braid and BX Hose Options
- ✓ Variety of Connection Methods to Work with Your Instrumentation

### M12CFM-RTD Series




M12CFM-P24STPC-RFSR-MINIDIN-3, cable assembly, shown smaller than actual size.

### Typical M12CFM Cable Configuration

M12CFM-P24STPC-RFSR-MINIDIN-3

Length in Meters

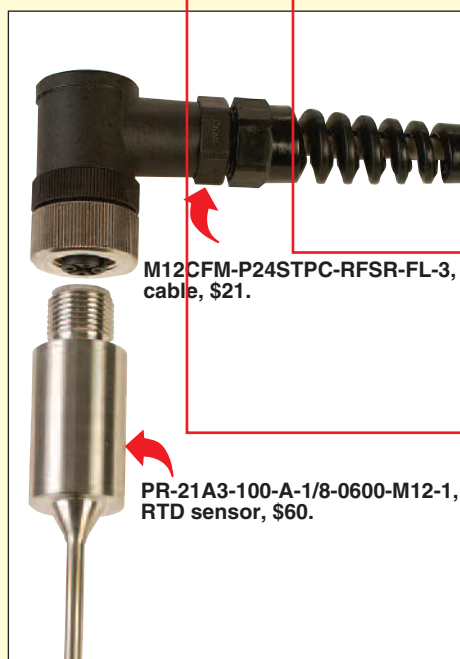

### Model Number Options Key

#### Back End Connector Options (Instrument Attachment)

MTPM	MTP 3-pin miniature plug connector
MTPF	MTP 3-pin miniature socket connector
OTPM	OTP 3-pin plug connector
OTPF	OTP 3-pin socket connector
TA3FM	3-pin audio plug connector
TA3FF	3-pin audio socket connector
TA4FM	4-pin audio plug connector
TA4FF	4-pin audio socket connector
MINIDIN	4-pin mini DIN plug connector
SFSR	M12 straight socket connector with strain relief
SMSR	M12 straight plug connector with strain relief
RFSR	M12 right angled socket connector with strain relief
RMSR	M12 right angled plug connector with strain relief
FL	150 mm (6") flying leads (minimum)

#### Front End Connector Options (Sensor Attachment)

SFSR	M12 straight socket connector with strain relief
SMSR	M12 straight plug connector with strain relief
RFSR	M12 right angled socket connector with strain relief
RMSR	M12 right angled plug connector with strain relief

#### Cable Options

T24SSPC	24 AWG stranded SPC, PFA insulated and jacketed
P24STPC	24 AWG stranded TPC, PVC insulated and jacketed

**Note:** For stainless steel over-braid, add "SB" to the end of the cable callout and per meter to the price.


For BX hose over the cable, add "BX" to the end of the cable callout and per meter to the price.




M12CFM-P24STPC-RFSR-MINIDIN-3, cable assembly, shown smaller than actual size.



M12 right angled socket connector with strain relief.

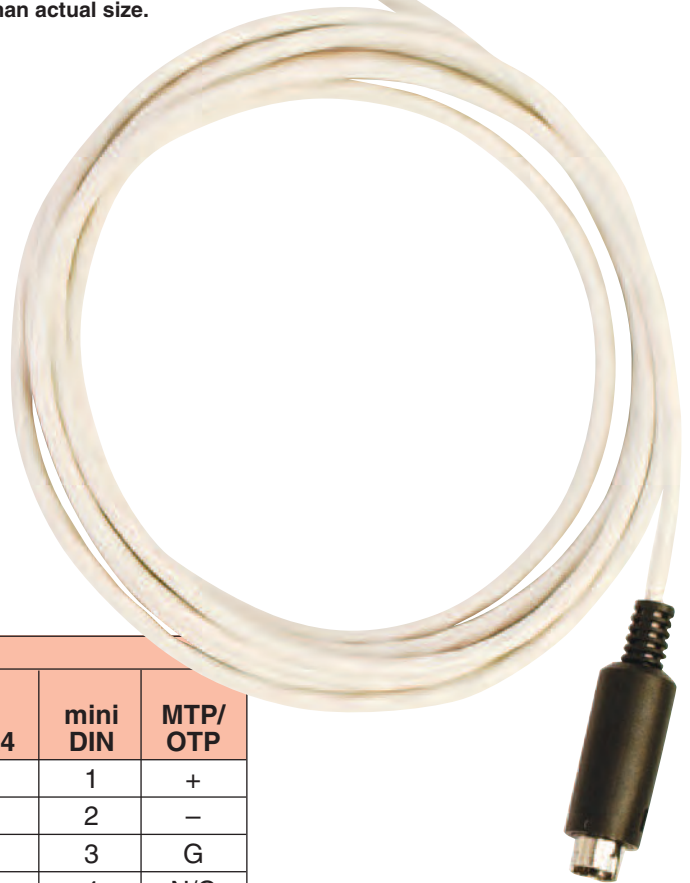

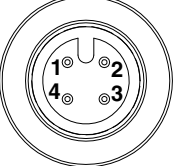 M12 Connector Sensor Side	Cable Wiring					
	M12 Connector Pin Number	Color	TA3	TA4	mini DIN	MTP/ OTP
	1	Brown	1	1	1	+
	2	White	2	2	2	-
	3	Blue	3	3	3	G
	4	Black	N/C	4	4	N/C

**MOST POPULAR MODELS HIGHLIGHTED!**

### To Order (Specify Model Number)

Model No.	Cable	Sensor Connector	Termination	Length (Meters)	Price
M12CFM-T24SSPC-SFSR-FL-3	PFA insulated and jacketed, 24 AWG stranded silver plated copper	M12 straight socket	150 mm (6") flying leads	3	
M12CFM-T24SSPC-SFSR-FL-5				5	
M12CFM-T24SSPC-SFSR-FL-10				10	
M12CFM-T24SSPC-SFSR-FL-15				15	
M12CFM-T24SSPC-SFSR-FL-20				20	
M12CFM-P24STPC-SRSR-FL-3	PVC insulated and jacketed, 24 AWG stranded tin plated copper	M12 right angled socket	150 mm (6") flying leads	3	
M12CFM-P24STPC-SRSR-FL-5				5	
M12CFM-P24STPC-SRSR-FL-10				10	
M12CFM-P24STPC-SRSR-FL-15				15	
M12CFM-P24STPC-SRSR-FL-20				20	

For longer cables, change last number in model number to the desired length in meters and add per meter, to the price.

To add a connector to the end of the cable, replace "FL" in the model number with the connector designation in the table and add the following to the price: "MTP" no additional charge, "OTP" no additional charge, for "TA3M", "TA3F", "TA4M", "TA4F" or "MINIDIN" add , for "SFSR", "RFSR", "SMSR" or "RMSR" add \$10.

For Stainless Steel overbraid, add "SB" to the end of the cable callout and add per meter to the price.

For BX Hose, add "BX" to the end of the cable callout and add per meter to the price.

**Ordering Examples:** M12CFM-T24SSPCSB-RFSR-MTPM-3, 4-conductor, 24 AWG, stranded silver plated copper conductors, PFA insulation and jacket and stainless steel braid 3 m long, M12 right angled plug connector with strain relief one end and MTP-male connector on the other.

M12CFM-P24STPC-RFSR-SMSR-5, 4-conductor, 24 AWG stranded tin plated copper conductors, PVC insulation and jacket, 5 m long, M12 right angled socket connector with strain relief one end and M12 straight plug connector with strain relief on the other.



## UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA  
Stamford, CT.

## CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)  
1-800-TC-OMEGA

## GERMANY

[www.omega.de](http://www.omega.de)

Deckenpfronn, Germany  
0800-8266342

## UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England  
0800-488-488

## FRANCE

[www.omega.fr](http://www.omega.fr)

Guyancourt, France  
088-466-342

## CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)

Karviná, Czech Republic  
596-311-899

## BENELUX

[www.omega.nl](http://www.omega.nl)

Amstelveen, NL  
0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters