


# Thermocouple Probes

## With M12 Moulded Connectors

M12 Series  
Starts at  
**£24<sup>75</sup>**



- ✓ Type J and K Thermocouple
- ✓ Insulated Junctions
- ✓ -50 to 90°C Connector Temperature Range
- ✓ 304 Stainless Steel Probe (Type J) and Inconel 600 Probe (Type K)
- ✓ With or Without Process Mounting Thread

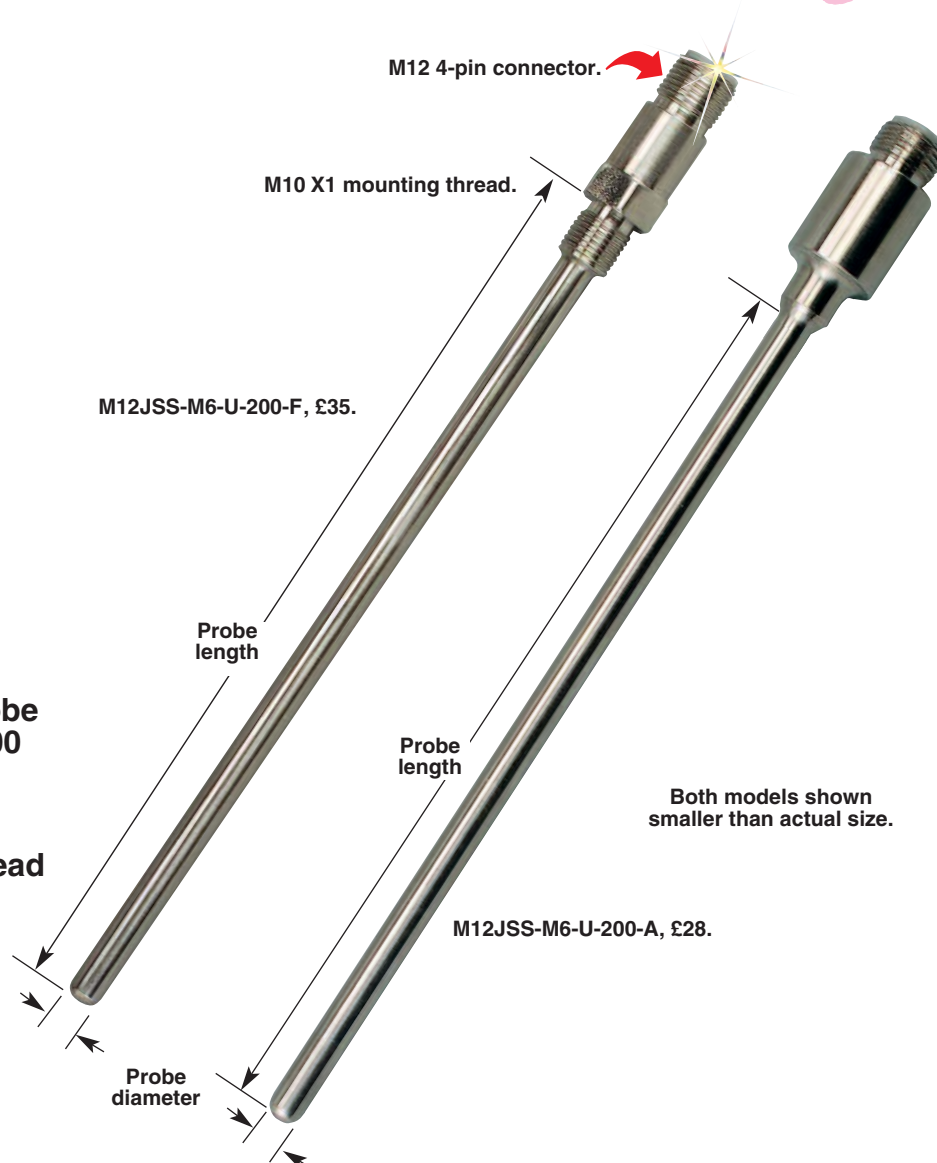

**MOST POPULAR MODELS HIGHLIGHTED!**

To Order (Specify Model Number)						
Model Number	Price		Probe Length	Thermocouple Type	Sheath Material	Mounting Thread
	3 mm Dia	6 mm Dia				
M12JSS-(*)-U-200-A	£24.75	£28	200 mm	J	304 SS	None
M12JSS-(*)-U-200-G	31.50	37	200 mm	J	304 SS	G <sup>1</sup> / <sub>2</sub>
M12JSS-(*)-U-200-F	31.50	37	200 mm	J	304 SS	M10x1
M12KIN-(*)-U-200-A	24.75	30	200 mm	K	Inconel 600	None
M12KIN-(*)-U-200-G	31.50	37	200 mm	K	Inconel 600	G <sup>1</sup> / <sub>2</sub>
M12KIN-(*)-U-200-F	31.50	37	200 mm	K	Inconel 600	M10x1

(\*) Insert "M3" for 3 mm or "M6" for 6 mm probe diameter.

For longer lengths, enter the required length in millimetres to the model number and add £0.35 per 25 mm to the price for 304 SS sheathed Type J or £0.45 per 25 mm for Inconel 600 sheathed Type K thermocouples.

**Ordering Examples:** M12JSS-M3-U-200-E, Type J thermocouple with 3 mm diameter, 200 mm long 304 stainless steel sheath, stainless steel transition and M12 connector, £31.50

M12KIN-M3-U-200-A, Type K thermocouple with 3 mm diameter, 200 mm long Inconel 600 sheath, stainless steel transition and M12 connector, £24.75.

# omega.co.uk®

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

**www.omega.co.uk**



#### UNITED STATES

[www.omega.com](http://www.omega.com)

1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)

Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)

Deckenfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)

Manchester, England  
0800-488-488  
+44-(0)161-777-6611

#### FRANCE

[www.omega.fr](http://www.omega.fr)

0800-466-342

#### BENELUX

[www.omega.nl](http://www.omega.nl)

0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers, Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters