

Programmable Timer



PTC-12
£90



- ✓ 9 Programmable Modes
- ✓ 6 Timing Ranges
- ✓ Security Code
- ✓ 2- or 1-Timed plus 1 Instantaneous Contact
- ✓ Programmable Reset Function
- ✓ External Hold and Reset
- ✓ LED Status and Timing Indicators

PTC-12, £90, shown larger than actual size

The PTC-12 programmable timer, packaged in a standard $\frac{1}{6}$ DIN 48 x 48 mm (1.9 x 1.9") housing, is an extremely versatile product offering nine operating modes applied to two timed output relay contacts. When only one of the timers is being used, the other output acts as a set of instantaneous changeover contacts. The single model provides timing from 0.1 seconds to 100 hours.


Ambient Conditions:

Working Temp:
0 to 50°C (32 to 122°F)

Storage Temp:
0 to 70°C (32 to 158°F)

Approvals: Complies with CE directives EN50081-1 and EN50082-1 for EMC and EN61010-1 for low voltage

Weight: 150 g (5.3 oz)

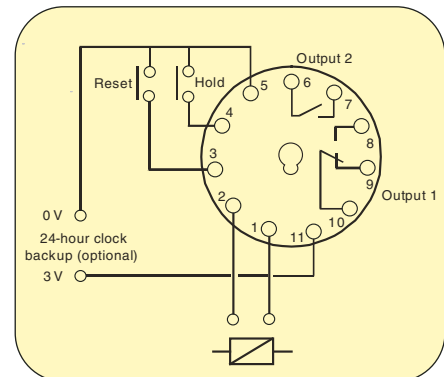

Specifications

Timing Ranges:

0 to 999.9 sec, 0 to 9999 sec,
0 to 9999 min, 0 to 99 min 59 sec,
0 to 99 hr 59 min, 23:59 in 24 hr clock mode

Timing Modes:

DE, DDE, DP, CCT, DE-2, IT-2,
DE-IT, DD-2, 24-hour clock

Supply Voltage: 12 to 24 Vac/Vdc

Supply Variation:

±10% of supply voltage

Battery Backup: External 3 Vdc to retain clock on 24 hr mode only at loss of supply voltage


Power Drain: 3 Va max

Contact Ratings:

OP1: 8 A @ 240 Vac, SPDT

OP2: 5 A @ 240 Vac resistive, SPST

Reset Time: 100 msec max

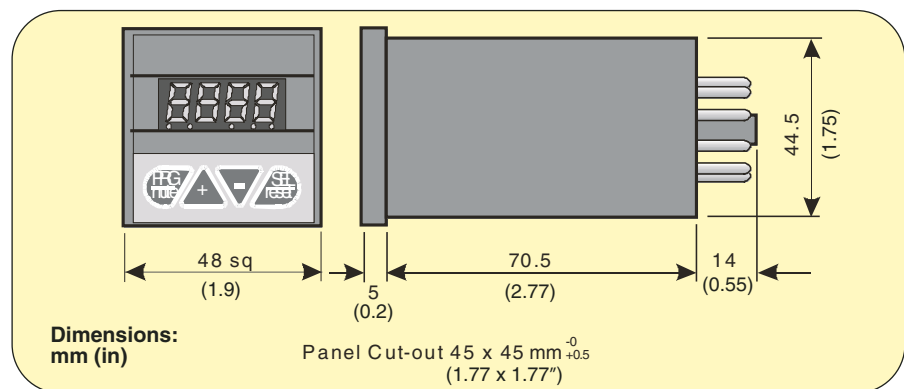

AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model Number)		
Model No.	Price	Description
PTC-12	£90	Programmable timer
PE-1402	53	Reference Book: Instrumentation and Control Systems Documentation

Comes with complete operator's manual and mounting socket.
Ordering Example: PTC-12, programmable timer, £90 .

omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA

Stamford, CT.

CANADA

www.omega.ca

Laval(Quebec)

1-800-TC-OMEGA

GERMANY

www.omega.de

Deckenpfronn, Germany

0800-8266342

UNITED KINGDOM

www.omega.co.uk

Manchester, England

0800-488-488

FRANCE

www.omega.fr

088-466-342

CZECH REPUBLIC

www.omegaeng.cz

Karviná, Czech Republic

596-311-899

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters